

Product Area Male cable connector moulded, shielded
M12 connectors A-Coding

 
serie 763

Pole 8
Article number 79 3579 32 08


illustration



scale drawing



Contact Arrangement

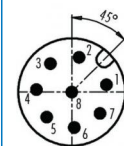	geschirmt	nicht geschirmt
	1 weiß	1 weiß
	2 braun	2 braun
	3 grün	3 grün
	4 gelb	4 gelb
	5 grau	5 grau
	6 rosa	6 rosa
	7 blau	7 blau
	8 Gehäuse-Schirm	8 Schirm/shield

Technical data

Common values

Connector Design	Male cable connector
Connector locking system	Screw-locking
Termination	crimp, overmoulded on cable
Wire gauge (mm)	0,25 mm ²
Wire gauge (AWG)	24
Upper temperature	+85 °C
Lower temperature	-25 °C

Electrical values

Rated voltage	60 V
Rated impulse voltage	800 V
Pollution degree	3
Overvoltage category	II
Material group	II
Rated current (40 °C)	2 A
Volume resistivity	≤ 3 mΩ
Degree of protection	IP 67
Mechanical operation	>100 mating cycles

Material

Material of contact	CuZn (brass)
Contact plating	Au (gold)
Material of contact body	PUR
Material of housing	PUR

Cable data

material housing	PUR
insulation single lead	PVC
single lead structure	19 x 0,127
cable sheath Ø	6
conductor resistance	73 Ω/km
temperature range cable movable c from	-5
temperature range cable movable c to	70
temperature range cable fixed c from	-25
temperature range cable fixed c to	70
bending radius cable fixed	60 mm
bending radius cable movable	120 mm

Contacts 8: Cable length 2 m, cable 7 x 0,25 PUR, male cable connector moulded, shielded