




Back

Selected Cable: 8497

End View	Plug	Cord	Connector	End View
NONE	NONE		NONE	NONE

Cord View

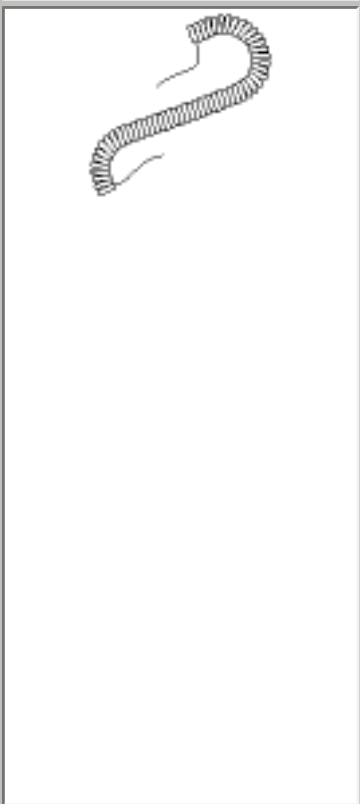

Part Number	8497
Category	retractile cords
Shielding	Beldfoil Aluminum-Polyester shield 1 Conductor
Jacket Color	Black
Length Feet	11.5
Length Meters	.292 - 1.8
Temperature Rating	90 C°C
Packaging Units Per Carton	S-10, S-25, B50
AWG Stranding	23 (21x36)
Nominal OD Inch	0.25
Nominal OD millimeter	6.35
Rating	90V
Notes	Fits most Astatic and Turner. 3 conductors; 1 SHIELDED. See 9417 for 15ft extended length version.

Approvals

Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

