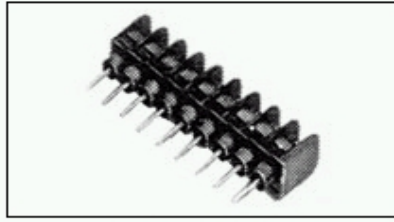


SSB6CF020341 Product Details

[Share](#) | [Print](#) | [Email](#)


SSB6CF020341

Barrier Strips

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Dual Barrier
- Block Style = Closed Bottom
- 9.53 mm Centerline
- Vertical Mount Angle

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 1-1437412-7

Superseded

[Contact Product Information Center](#)

[Add to My Part List](#) |
 [Request Sample](#) |
 [Find Similar Products](#) |
 [Buy Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Barrier Strip • Block Style = Closed Bottom • Mount Angle = Vertical • Mounting Insert = Without <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Mounting Options = None • Mounting Style = Open End Position • Mounting Ears = With <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Top Hardware = Quick Connect Blades <p>Body Features:</p> <ul style="list-style-type: none"> • Barrier Style = Single Row, Dual Barrier • Terminal Style = Non-Feed Through 	<p>Contact Features:</p> <ul style="list-style-type: none"> • Blade Size = 4.75 x 0.51 [.187 x .020] • Quick Connect Blade Style = 45°, Two Sided <p>Housing Features:</p> <ul style="list-style-type: none"> • Centerline (in [mm]) = 0.375 [9.53] <p>Configuration Features:</p> <ul style="list-style-type: none"> • Number of Positions = 2 • Number of Levels = Single <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C • RoHS/ELV Compliance History = Always was RoHS compliant <p>Other:</p> <ul style="list-style-type: none"> • Brand = Buchanan • Comment = Other options available upon request, consult our Product Information Center.

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

