


TSB150008DS Product Details

[Live Product Chat](#)

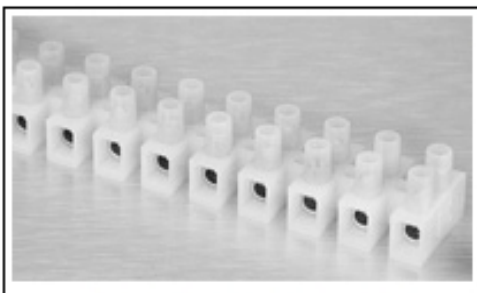

TSB150008DS (6-1437387-3)

TE Part Number: 6-1437387-3

Superseded

[Add to Part List](#)
[Search for Replacement Parts](#)

Europa Terminal Blocks

[Converted to EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Terminal Block
- 13.50 mm Centerline
- Number of Circuits = 8
- Wire Range = 0.80-8.00; [18-8] mm [AWG]
- With Wire Protection

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

onlinecomponents.com
THE ONLINE DISTRIBUTOR OF ELECTRONIC COMPONENTS

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Terminal Block
- [Number of Circuits](#) = 8
- [Integrated Fuse](#) = No
- Color = Natural
- Screw Size = M4
- Screw Material = Steel
- CSA File No. = LR28387
- UL Recognized = File No. E60677

Mechanical Attachment:

- Screw Plating = Bright Zinc/Chrome

Electrical Characteristics:

- Current Rating (Amps.) = 40
- Voltage Rating (VAC) = 300
- Wire Protector Material = Stainless Steel

Body Related Features:

- [Centerline \(mm \[in\]\)](#) = 13.50 [0.532]
- [Wire Range \(mm \[AWG\]\)](#) = 0.80-8.00; [18-8]
- [Wire Protection](#) = With
- [Ground](#) = Without
- [Series](#) = TSB1500
- Flammability Rating = UL 94V-2

Contact Related Features:

- Contact Material = Brass
- Contact Mating Area Plating Material = Tin

Housing Related Features:

- Housing Material = Polyamide

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Converted to comply with RoHS directive

Conditions for Usage:

- [Temperature Range \(°C\)](#) = -35 - +100

Other:

- Brand = Buchanan