




## 4PCV-03-007 Product Details

[Share](#) | [Print](#) | [Email](#)

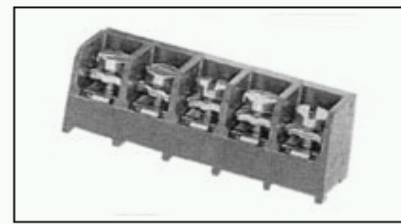

4PCV-03-007

### Barrier Strips

Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 8.26 mm Centerline
- Vertical Mount Angle

[View all Features](#)

TE Internal Number: 796607-6  
**Superseded**  
 Search for Replacement Parts

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [4PCV-XX-007 ASSEMBLY \(PDF, English\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Barrier Strip
- [Block Style](#) = Open Bottom with Standoffs
- [Mount Angle](#) = Vertical
- [Screw Material](#) = Steel
- [Mounting Insert](#) = Without

#### Mechanical Attachment:

- [Mounting Options](#) = None
- [Screw Plating](#) = Bright Zinc/Chrome
- [Mounting Style](#) = Direct (All Positions Filled)
- [Mounting Ears](#) = Without

#### Electrical Characteristics:

- [Top Hardware](#) = Binding Combo Head
- [Screw Head Type](#) = Phil-Slot
- [Current Rating, Max. \(A\)](#) = UL: 20A, CSA: 25A

#### Body Features:

- [Barrier Style](#) = Single Row, Tri-Barrier
- [Terminal Style](#) = Printed Circuit Pin 5.08 [.200]
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-3.00<sup>2</sup> [22-12]

#### Housing Features:

- [Centerline \(in \[mm\]\)](#) = 0.325 [8.26]

#### Configuration Features:

- [Number of Positions](#) = 3
- [Number of Levels](#) = Single

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

#### Other:

- [Brand](#) = Buchanan
- [Comment](#) = Other options available upon request, consult our Product Information Center.

### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

### Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

