




Search by Keyword or Part #

8PCV-10 Product Details

Have a Question?

Chat with a Product Information Specialist

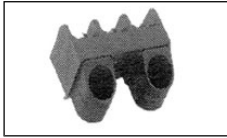

8PCV-10

TE Internal Number: 2-1437658-9

Superseded

[Search for Replacement Parts](#)

Barrier Strips

[Not reviewed for RoHS Compliance](#)

Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 11.10 mm Centerline
- Vertical Mount Angle

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#)

[Request Sample](#)

[Find Similar Products](#)

[Buy Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Barrier Strip • Mount Angle = Vertical • Screw Material = Steel • Mounting Ears = Without • Comment = Do not order Screw and Captive Clamp in combination with other top hardware.; Other options available upon request, consult our Product Information Center. <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Screw Plating = Bright Zinc/Chrome • Mounting Style = Direct (All Positions Filled) <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Top Hardware = Wire Clamp Combo Head • Number of Levels = Single • Current Rating (A) = 30 • Screw Head Type = Slotted • Voltage (VAC) = 600 • Mounting Insert = Without 	<p>Termination Related Features:</p> <ul style="list-style-type: none"> • Terminal Plating = Bright Tin <p>Body Related Features:</p> <ul style="list-style-type: none"> • Barrier Style = Single Row, Tri-Barrier • Block Style = Open Bottom with Standoffs • Centerline (in [mm]) = 0.4375 [11.10] • Number of Positions = 10 • Terminal Style = Printed Circuit Pin 5.08 [.200] • Terminal Material = Copper Alloy <p>Contact Related Features:</p> <ul style="list-style-type: none"> • Mounting Options = None <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = Not reviewed for ELV/RoHS compliance • Lead Free Solder Processes = Not reviewed for lead free solder process <p>Other:</p> <ul style="list-style-type: none"> • Brand = Buchanan



Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:

[Twitter](#) [Facebook](#) [Flickr](#) [LinkedIn](#) [YouTube](#)