


4PCV-06-004 Product Details

[Share](#)
[Print](#)
[Email](#)

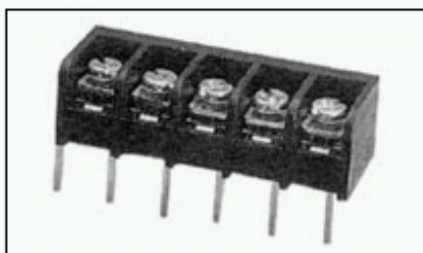

4PCV-06-004

Barrier Strips

[Not reviewed for RoHS Compliance](#)

Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 8.26 mm Centerline
- Vertical Mount Angle

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TE Internal Number: 7-1437648-9

 **Superseded**

[Search for Replacement Parts](#)

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Barrier Strip
- [Mount Angle](#) = Vertical
- Screw Material = Steel
- Mounting Ears = With

Mechanical Attachment:

- Screw Plating = Bright Zinc/Chrome
- Mounting Style = Open End Position

Electrical Characteristics:

- [Top Hardware](#) = Wire Clamp Combo Head
- Number of Levels = Single
- Screw Head Type = Slotted
- Current Rating, Max. (A) = UL: 20A, CSA: 25A
- Mounting Insert = Without

Body Features:

- [Barrier Style](#) = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- [Centerline \(in \[mm\]\)](#) = 0.325 [8.26]
- Number of Positions = 6
- [Terminal Style](#) = Printed Circuit Pin 5.08 [.200]
- Wire Range (mm [AWG]) = 0.30-3.00² [22-12]

Contact Features:

- Mounting Options = None
- Mounting Bushing = With

Industry Standards:

- [RoHS/ELV Compliance](#) = Not reviewed for ELV/RoHS compliance
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process

Other:

- Brand = Buchanan
- Comment = Do not order Screw and Captive Clamp in combination with other top hardware.; Other options available upon request, consult our Product Information Center.

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

