


## 4PCR-03 Product Details

[Live Product Chat](#)

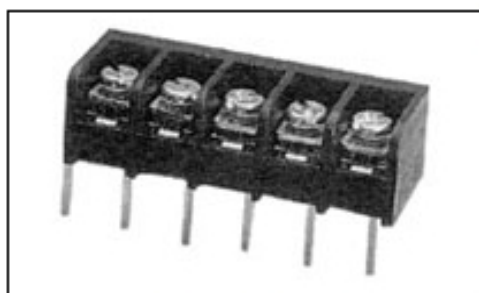

**4PCR-03**

TE Part Number: 1-1437648-9

**Superseded**

[Add to Part List](#)  
[Search for Replacement Parts](#)

### Barrier Strips, Barrier Strip Sockets

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 8.26 mm Centerline
- Right Angle Mount Angle

[View all Features](#) | 
 [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- None Available

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Barrier Strip
- [Mount Angle](#) = Right Angle
- Number of Positions = 3
- CSA File No. = LR30811
- UL Recognized = File No. E54800
- Screw Material = Steel
- Mounting Ears = Without
- Comment = Other options available upon request, consult our Product Information Center.

#### Mechanical Attachment:

- Screw Plating = Bright Zinc/Chrome
- Mounting Style = Direct (All Positions Filled)

#### Electrical Characteristics:

- [Top Hardware](#) = Wire Clamp Combo Head
- Number of Levels = Single
- End Barriers = Without
- Bracket = Without
- Screw Head Type = Slotted
- Mounting Insert = Without

#### Body Related Features:

- [Barrier Style](#) = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- [Centerline \(in \[mm\]\)](#) = 0.325 [8.26]
- Number of Rows = Single
- [Terminal Style](#) = Printed Circuit Pin
- Wire Range (mm [AWG]) = 0.30-3.00<sup>2</sup> [22-12]

#### Contact Related Features:

- Mounting Options = None

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Other:

- Brand = Buchanan