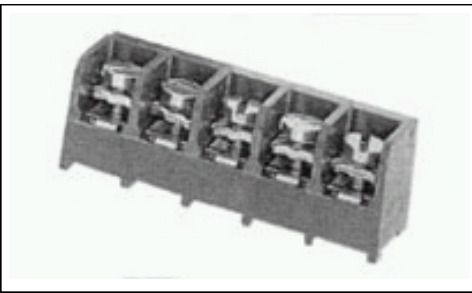


## 6PCV -21 Product Details

 [Live Product Chat](#)

**6PCV -21**

TE Part Number: 2 - 1437654 - 8

 [Obsolete](#)
[Add to Part List](#)  
[Search for Replacement Parts](#)

### Barrier Strips, Barrier Strip Sockets

[Not reviewed for RoHS Compliance](#)
**Product Highlights:**

- ? Barrier Strip
- ? Barrier Style = Single Row, Tri -Barrier
- ? Block Style = Open Bottom with Standoffs
- ? 9.53 mm Centerline
- ? Vertical Mount Angle

[View all Features](#) | [Find Similar Products](#)
**Quick Links**

[Check Pricing & Availability](#)  
[Search for Tooling](#)  
[Product Feature Selector](#)  
[Contact Us About This Product](#)

### Documentation & Additional Information

**Product Drawings:**

- ? None Available

**Catalog Pages/Data Sheets:**

- ? None Available

**Product Specifications:**

- ? None Available

**Application Specifications:**

- ? None Available

**Instruction Sheets:**

- ? None Available

**CAD Files:**

- ? None Available

**Additional Information:**

- ? [Product Line Information](#)

**Related Products:**

- ? [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- ? [Product Type](#) = Barrier Strip
- ? [Mount Angle](#) = Vertical
- ? Number of Positions = 21
- ? CSA File No. = LR30811
- ? UL Recognized = File No. E54800
- ? Screw Material = Steel
- ? Mounting Ears = Without
- ? Comment = Do not order Screw and Captive Clamp in combination with other top hardware.; Other options available upon request, consult our Product Information Center.

**Mechanical Attachment:**

- ? Screw Plating = Bright Zinc/Chrome
- ? Mounting Style = Direct (All Positions Filled)

**Electrical Characteristics:**

- ? [Top Hardware](#) = Wire Clamp Combo Head
- ? Number of Levels = Single
- ? End Barriers = Without
- ? Bracket = Without
- ? Screw Head Type = Slotted
- ? Mounting Insert = Without

**Body Related Features:**

- ? [Barrier Style](#) = Single Row, Tri -Barrier
- ? Block Style = Open Bottom with Standoffs
- ? [Centerline \(in \[mm\]\)](#) = 0.375 [9.53]
- ? Number of Rows = Single
- ? [Terminal Style](#) = Printed Circuit Pin 5.08 [.200]

**Contact Related Features:**

- ? Mounting Options = None

**Industry Standards:**

- ? [RoHS/ELV Compliance](#) = Not reviewed for ELV/RoHS compliance
- ? [Lead Free Solder Processes](#) = Not reviewed for lead free solder process

**Other:**

- ? Brand = Buchanan