


## 8PCV-09 Product Details

 [Live Product Chat](#)

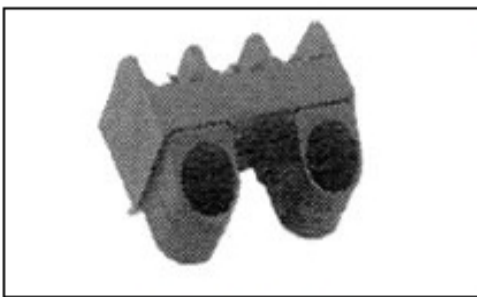

**8PCV-09**

TE Part Number: 2-1437658-8

 **Superseded**

[Add to Part List](#)  
[Search for Replacement Parts](#)

### Barrier Strips, Barrier Strip Sockets

[Not reviewed for RoHS Compliance](#)

#### Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 11.10 mm Centerline
- Vertical Mount Angle

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- None Available

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Barrier Strip
- [Mount Angle](#) = Vertical
- Number of Positions = 9
- CSA File No. = LR30811
- UL Recognized = File No. E54800
- Screw Material = Steel
- Mounting Ears = Without
- Comment = Do not order Screw and Captive Clamp in combination with other top hardware.; Other options available upon request, consult our Product Information Center.

#### Mechanical Attachment:

- Screw Plating = Bright Zinc/Chrome
- Mounting Style = Direct (All Positions Filled)

#### Electrical Characteristics:

- [Top Hardware](#) = Wire Clamp Combo Head
- Number of Levels = Single
- End Barriers = Without
- Bracket = Without
- Current Rating (Amps.) = 30
- Screw Head Type = Slotted
- Voltage (VAC) = 600
- Mounting Insert = Without

#### Termination Related Features:

- Terminal Plating = Bright Tin

#### Body Related Features:

- [Barrier Style](#) = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- [Centerline \(in \[mm\]\)](#) = 0.4375 [11.10]
- Number of Rows = Single
- [Terminal Style](#) = Printed Circuit Pin 5.08 [.200]
- Terminal Material = Copper Alloy

#### Contact Related Features:

- Mounting Options = None

#### Industry Standards:

- [RoHS/ELV Compliance](#) = Not reviewed for ELV/RoHS compliance
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process

#### Other:

- Brand = Buchanan