



TE CONNECTIVITY (TE)
BC6-Q308-04=BC6 ASSEMBLY

Buchanan | [BC6 Series](#)

1546781-1
 TE Internal Number: 1546781-1
 Alias ID: BC6-Q308-04

[EU RoHS Compliant](#)

[EU ELV Compliant](#)

Barrier Style **Tri-Barrier**

Bottom Termination Style **Quick Connects**

Current Rating (A) **20**

Number of Positions **4**

Centerline (Pitch) **9.53mm [.375in]**

[See All Features](#)

✓ Active

[PRODUCT DRAWING](#)
 English

[3D PDF](#)

[See All Documentation](#)

North America ▼

DISTRIBUTOR	QUANTITY	DATE AS OF
MASTER ELECTRONICS CORP. 1-888-473-5297	252	2017/09/26

GET SAMPLE	
SAVE TO LIST ▼	
CHECK FOR TOOLING	
FIND SIMILAR PRODUCTS	

DOCUMENTATION

FEATURES

PRODUCT COMPLIANCE

Product Drawings

[BC6-Q308-XX ASSEMBLY](#)

PDF
English

CAD Files

[3D PDF](#)

PDF
3D

[Customer View Model](#)

2D_DXF.ZIP
English

[Customer View Model](#)

3D_IGS.ZIP
English

[Customer View Model](#)

3D_STP.ZIP

Catalog Pages/Data Sheets

[BUCHANAN TERMINAL BLOCKS CATALOG - BARRIER STRIPS](#)

PDF

English

[1-1773458-2_BARRIER_STRIPS_QUICK_REFERENCE_GUIDE](#)

PDF

English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Block Style **Turret (Insulated)**Product Type **Barrier Strip**

Configuration Features

Number of Positions **4**Number of Rows **1**Number of Levels **1**

Electrical Characteristics

Current Rating (A) **20**Voltage (V) **300**

Body Features

Barrier Style **Tri-Barrier**Color **Black**

Contact Features

Terminal Plating Finish **Bright**Terminal Material **Copper Alloy**Terminal Plating Material **Tin**

Termination Features

Bottom Termination Style **Quick Connects**

Mechanical Attachment

Connector Mounting Type **Panel**Screw Size **6-32**Mounting Ears **With**Mounting Options **End Mounting Ears**Screw Material **Steel**Screw Plating Material **Zinc Chromate**Top Hardware **Wire Clamp Combo Head**

Mounting Insert **Without**

Screw Head Type **Combo Phil-Slot**

Mounting Angle **Vertical**

Housing Features

Centerline (Pitch) **9.53 mm [.375 in]**

Housing Material **Thermoplastic**

Dimensions

Wire Range **22 – 12AWG [.326 – 3.31 mm²]**

Length **55.601 mm [2.189 in]**

Industry Standards

UL Flammability Rating **UL 94V-0**

Packaging Features

Packaging Method **Package**

Packaging Quantity **120**


Statement of Compliance

[Statement of Compliance](#)
PDF

Compatible Products

[> Contact Product Support](#)

Also in the Series | [BC6 Series](#)

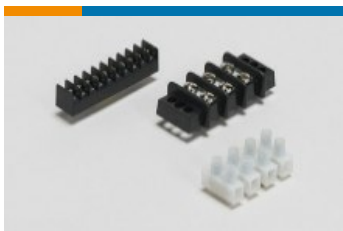

[Barrier Strips \(2135\)](#)

 
Customers Also Bought

[BARRIER STRIPS](#)

[CHASSIS PANEL MOUNT RESISTORS](#)

[THROUGH-HOLE RESISTORS](#)

[THROUGH-HOLE RESISTORS](#)



**BC6-F308-06, BC6
SERIES**
1986800-6



HSA25 25K 5%
HSA2525KJ



YR1 0.1% 34R8
YR1B34R8CC



YR1 0.1% 17R4
YR1B17R4CC

About TE Connectivity

For Partners

Customer Support

CALL US

LIVE CHAT

United States

Our Company

Events

TE News Center

Careers


Investors


Corporate Responsibility

Terms and Conditions of
Sale

Distributors

Suppliers

 Email or Call Us

 Find Authorized Distributors

 What's New on TE.com

 Product FAQs

Select Country & Language

United States (EN)

Germany (DE)

China (中文)

Japan (日本語)

Afghanistan (EN) ▼

Find Your Country ▼

Terms of Use | Privacy | Cookie Policy | Accessibility | Site Map



© 2017 TE Connectivity Corporation. All Rights Reserved