

TE CONNECTIVITY (TE)
JC6-P108-25=JC6 ASSY

Buchanan | JC6 Series

5-796985-1
 TE Internal Number: 5-796985-1
 Alias ID: JC6-P108-25

[EU RoHS Compliant](#)
[EU ELV Compliant](#)

Barrier Style **Dual Barrier**

Bottom Termination Style **Printed Circuit Pin**

Current Rating (A) **5, 20**

Number of Positions **25**

Centerline (Pitch) **9.53mm [.375in]**
[See All Features](#)

✓ Active

[PRODUCT DRAWING](#)
 English

[See All Documentation](#)

North America ▼

Contact us to request pricing, availability and customization options.

REQUEST ADDITIONAL INFORMATION



GET SAMPLE



SAVE TO LIST ▼



CHECK FOR TOOLING



FIND SIMILAR PRODUCTS



DOCUMENTATION

FEATURES

PRODUCT COMPLIANCE

Product Drawings

[JC6-P108-106-XX ASSEMBLY](#)
 PDF
English

Catalog Pages/Data Sheets

[BUCHANAN TERMINAL BLOCKS CATALOG - BARRIER STRIPS](#)
 PDF
English

[1-1773458-2_BARRIER_STRIPS_QUICK_REFERENCE_GUIDE](#)
 PDF
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.


Product Type Features	Connector & Contact Terminates To	Printed Circuit Board
	Block Style	Flat
	Product Type	Barrier Strip
Configuration Features	Number of Positions	25
	Number of Rows	1
	Number of Levels	1
Electrical Characteristics	Current Rating (Max) (A)	20
	Current Rating (A)	5, 20
	Voltage (V)	300, 600
Body Features	Barrier Style	Dual Barrier
	Color	Black
Contact Features	Terminal Plating Finish	Bright
	Terminal Material	Copper Alloy
	Terminal Plating Material	Tin
Termination Features	Bottom Termination Style	Printed Circuit Pin
Mechanical Attachment	Screw Size	6-32
	Mounting Ears	Without
	Mounting Options	None
	Screw Material	Steel
	Screw Plating Material	Zinc Chromate
	Top Hardware	Wire Clamp Combo Head
	Mounting Insert	Without
	Screw Head Type	Wire Clamp Combo Head
	Mounting Angle	Vertical
Housing Features	Centerline (Pitch)	9.53 mm [.375 in]
	Housing Material	Thermoplastic

Dimensions	Wire Range	22 - 12AWG [.3 - 3 mm²]
	Length	239.674 mm [9.436 in]
Industry Standards	UL Flammability Rating	UL 94V-0
	Packaging Features	
	Packaging Method	Package
	Packaging Quantity	30
Other	Comment	Do not order screw and captive clamp in combination with other top hardware., Other options available upon request, consult our Product Information Center.
	Statement of Compliance	Statement of Compliance PDF

Compatible Products



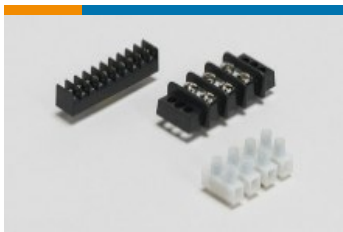

[Contact Product Support](#)

Also in the Series | [JC6 Series](#)



Barrier Strips (2135)

Customers Also Bought

UNSCREENED BACKSHELLS & ADAPTERS	RUGGEDIZED BACKSHELLS & ADAPTERS	UNSCREENED BACKSHELLS & ADAPTERS	RUGGEDIZED BACKSHELLS & ADAPTERS
			
<p>202M112-19B 202M112-19B</p>	<p>TXR40AC00-2212AI TXR40AC00-2212AI</p>	<p>202M110-19B 202M110-19B</p>	<p>TXR40AC00-1610AI TXR40AC00-1610AI</p>

Our Company

Events

TE News Center

Careers

Investors

Corporate Responsibility

Terms and Conditions of Sale

Distributors

Suppliers

 Email or Call Us

 Find Authorized Distributors

 What's New on TE.com

 Product FAQs

Select Country & Language

United States (EN)

Germany (DE)

China (中文)

Japan (日本語)

Afghanistan (EN) ▼

Find Your Country ▼

