


## Product Details for TSB100003

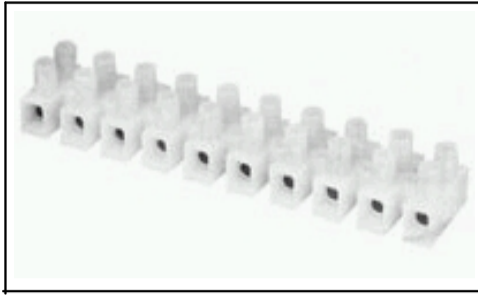

### TSB100003

Tyco Part Number: 3 - 1437387 - 8

[Active](#)

## Europa Terminal Blocks

[RoHS Compliant \(Statement of Compliance\)](#)

### Product Highlights:

- ? Terminal Block
- ? 12.00 mm Centerline
- ? Number of Circuits = 3
- ? Wire Range = 0.30 - 8.00; [22 - 8] mm [AWG]
- ? Without Wire Protection

[View all Features](#)

## Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

## Documentation & Additional Information

### Product Drawings:

- ? None Available

### Catalog Pages/Data Sheets:

- ? None Available

### Product Specifications:

- ? None Available

### Application Specifications:

- ? None Available

### Instruction Sheets:

- ? None Available

### CAD Files:

- ? None Available

### Additional Information:

- ? [Product Line Information](#)

### Additional Product Images:

- ? [Line Drawing](#)

### Related Products:

- ? [Tooling](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- ? [Product Type](#) = Terminal Block
- ? [Number of Circuits](#) = 3
- ? [Integrated Fuse](#) = No
- ? Color = Natural
- ? Screw Size = M3.5
- ? Screw Material = Steel
- ? UL Recognized = File No. E63810

### Mechanical Attachment:

- ? Screw Plating = Bright Zinc/Chrome

### Electrical Characteristics:

- ? Current Rating (Amps.) = 50
- ? Voltage Rating (VAC) = 250

### Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 12.00 [0.472]
- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 - 8.00; [22 - 8]
- ? [Wire Protection](#) = Without
- ? [Ground](#) = Without
- ? [Series](#) = TSB1000
- ? Flammability Rating = UL 94V - 2
- ? CSA File No. = LR28387

### Contact Related Features:

- ? Contact Material = Brass
- ? Contact Mating Area Plating = Tin

### Housing Related Features:

- ? Housing Material = Polyamide

### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Converted to comply with RoHS directive

### Conditions for Usage:

- ? [Temperature Range \(°C\)](#) = 105

### Other:

- ? Brand = Buchanan