


TSB5000431 Product Details

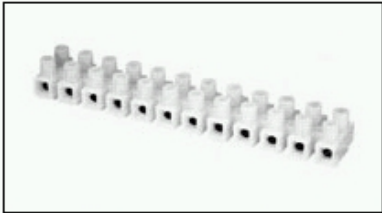

TSB5000431
(1-1437388-0)

TE Internal Number: 1-1437388-0

Superseded

[Search for Replacement Parts](#)

Europa Terminal Blocks

[Not EU RoHS or ELV Compliant](#) ([Find RoHS Compliant Alternates](#))

Product Highlights:

- 10.00 mm Centerline
- Number of Circuits = 4
- Wire Range = 0.30-6.00² [22-10] mm [AWG]
- Without Wire Protection
- Integrated Fuse = No

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information	
Product Drawings: • None Available Catalog Pages/Data Sheets: • None Available Product Specifications: • None Available Application Specifications: • None Available Instruction Sheets: • None Available CAD Files: • None Available	Additional Information: • Product Line Information Related Products: • Tooling

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: • Number of Circuits = 4 • Integrated Fuse = No • Color = Natural • Screw Size = M3 Screw • Screw Material = Steel • CSA File Number = LR28387 • UL File Number = E60677 Mechanical Attachment: • Screw Plating = Bright Zinc/Chrome Electrical Characteristics: • Current Rating (A) = 30 • Voltage Rating (VAC) = 250 Body Related Features: • Centerline (mm [in]) = 10.00 [0.394] • Wire Range (mm [AWG]) = 0.30-6.00² [22-10] • Wire Protection = Without • Ground = Without • Series = TSB500	Contact Related Features: • Contact Base Material = Brass • Contact Plating, Mating Area, Material = Tin Housing Related Features: • Housing Material = Polyamide - GF • UL Flammability Rating = UL 94V-2 Industry Standards: • RoHS/ELV Compliance = Not ELV/RoHS compliant • Lead Free Solder Processes = Not relevant for lead free process Conditions for Usage: • Temperature Range (°C) = 105 Other: • Brand = Buchanan

BOOKMARK

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

 
Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

