


TSB200002DS Product Details

Have a Question?

Chat with a Product Information Specialist

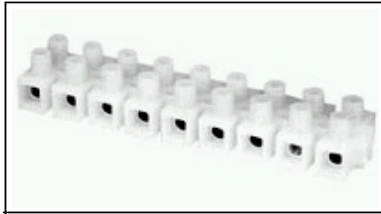

Europa Terminal Blocks

[Converted to EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? 14.50 mm Centerline
- ? Number of Circuits = 2
- ? Wire Range = 2.00 - 14.00; [14 - 6] mm [AWG]
- ? With Wire Protection
- ? Integrated Fuse = No

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TSB200002DS

(6 - 1437387 - 8)

TE Internal Number: 6 - 1437387 - 8



Superseded

[Search for Replacement Parts](#)

[Add to My Part List](#)



[Request Sample](#)



[Find Similar Products](#)



[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- ? None Available

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Number of Circuits](#) = 2
- ? [Integrated Fuse](#) = No
- ? Color = Natural
- ? Screw Size = M5
- ? Screw Material = Steel
- ? CSA File Number = LR28387
- ? UL File Number = E60677

Mechanical Attachment:

- ? Screw Plating = Bright Zinc/Chrome

Electrical Characteristics:

- ? Current Rating (A) = 65
- ? Voltage Rating (VAC) = 300
- ? Wire Protector Material = Stainless Steel

Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 14.50 [0.571]
- ? [Wire Range \(mm \[AWG\]\)](#) = 2.00 - 14.00; [14 - 6]
- ? [Wire Protection](#) = With
- ? [Ground](#) = Without
- ? [Series](#) = TSB2000

Contact Related Features:

- ? Contact Base Material = Brass
- ? Contact Plating, Mating Area, Material = Tin

Housing Related Features:

- ? Housing Material = Polyamide - GF
- ? UL Flammability Rating = UL 94V - 2

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Converted to comply with RoHS directive

Conditions for Usage:

- ? [Temperature Range \(°C\)](#) = -35 - +100

Other:

- ? Brand = Buchanan

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

