


## TSB200004DS Product Details

### Have a Question?

Chat with a Product Information Specialist

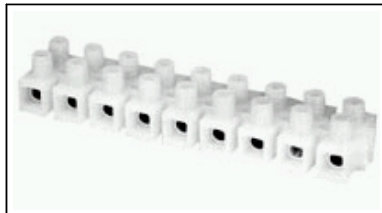

### Europa Terminal Blocks

[Converted to EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? 14.50 mm Centerline
- ? Number of Circuits = 4
- ? Wire Range = 2.00 - 14.00; [14 - 6] mm [AWG]
- ? With Wire Protection
- ? Integrated Fuse = No

[View all Features](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### TSB200004DS

(7 - 1437387 - 2)

TE Internal Number: 7 - 1437387 - 2



**Superseded**

[Search for Replacement Parts](#)

- [Add to My Part List](#)
- [Request Sample](#)
- [Find Similar Products](#)
- [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? None Available

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? None Available

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? None Available

#### CAD Files:

- ? None Available

#### Additional Information:

- ? [Product Line Information](#)

#### Related Products:

- ? [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Number of Circuits](#) = 4
- ? [Integrated Fuse](#) = No
- ? Color = Natural
- ? Screw Size = M5
- ? Screw Material = Steel
- ? CSA File Number = LR28387
- ? UL File Number = E60677

#### Mechanical Attachment:

- ? Screw Plating = Bright Zinc/Chrome

#### Electrical Characteristics:

- ? Current Rating (A) = 65
- ? Voltage Rating (VAC) = 300
- ? Wire Protector Material = Stainless Steel

#### Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 14.50 [0.571]
- ? [Wire Range \(mm \[AWG\]\)](#) = 2.00 - 14.00; [14 - 6]
- ? [Wire Protection](#) = With
- ? [Ground](#) = Without
- ? [Series](#) = TSB2000

#### Contact Related Features:

- ? Contact Base Material = Brass
- ? Contact Plating, Mating Area, Material = Tin

#### Housing Related Features:

- ? Housing Material = Polyamide - GF
- ? UL Flammability Rating = UL 94V - 2

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Converted to comply with RoHS directive

#### Conditions for Usage:

- ? [Temperature Range \(°C\)](#) = -35 - +100

#### Other:

- ? Brand = Buchanan

### Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

### Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

### Sign up for our eNewsletter

Enter your email address

### Follow Us On:



### Visit Us On:

