

SEARCH



[Search Only Products /](#)

Semiconductor & Chemical Pipe Markers



Semiconductor & Chemical Pipe Markers

Part Number:

91884

Material:

Vinyl

Dimensions:

0.5 in H x 2.25 in W

UOM:

Card of 28 Each

Color:

White on Green

ADD TO CART

1

PEOPLE ALSO VIEWED



OVERVIEW

B-946 vinyl is printed with weather resistant inks and is suited for use in outdoor applications where weatherability is a key consideration.

- Designed for permanent applications in severe indoor or outdoor environments
- High gloss, durable, flexible vinyl with a permanent cold temperature pressure sensitive acrylic adhesive
- Good chemical, oil and water resistance
- Average outdoor durability 8-10 years

SPECIFICATIONS

Arrow Direction	Left/Right
Average Outdoor Durability	8 to 10 Years
Material Number	B-946
Catalog Page #	277
Dimensions	0.5 in H x 2.25 in W
UOM	Card of 28 Each
Finish	Gloss
Indoor or Outdoor Use	Outdoor Use
Maximum Outside Pipe Diameter	0.75 in
Maximum Service Temperature °F	180 °F
Minimum Service Temperature °F	-40 °F

Overall Size	Fits Pipes 0.75" Dia. or smaller
Pipe Marker Mounting Style	Self-Adhesive
Pre-Printed Areas on Label	Pictogram Only
Product Number	91884
UPC	754473918842
Quantity per Card or Sheet	28
Thickness	0.004 in
Adhesive Type	Acrylic
Applications	Pipe & Valve Marking
Color	White on Green
Material	Vinyl
Reflective Type	Non-Reflective
Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Weather-Resistant

Solutions

[Floor Marking Guide](#)
[GHS Label Compliance](#)
[Lockout Tagout Compliance](#)
[Arc Flash Labeling Requirements](#)
[Cable and Wire Label Options](#)
[Product and Barcode Labeling](#)
[Brand Protection Solutions](#)

Services

[Lockout Tagout Services](#)
[Arc Flash Services](#)
[Confined Space Services](#)
[Visual Workplace Services](#)
[Hazcom GHS Services](#)
[Software Programming & Integration](#)
[Label Template & File Conversion](#)
[Printer Use & Training](#)
[Printer Preventative Maintenance](#)
[Toll and Custom Coating](#)
[Authentication & Tracking Services](#)

Help

[Contact Us](#)
[Knowledge Center](#)
[Printer Drivers & Firmware](#)
[Brady Software Updates](#)
[Safety Data Sheets](#)
[Technical Data Sheets](#)
[WEEE-RoHS Compliance](#)
[Product Certification](#)
[Printer Registration](#)

Resources

[Find a Distributor](#)
[Printer Selection Tool](#)
[Label Selection Tool](#)
[Digital Catalog](#)
[Request a Catalog](#)
[Interactive Facility Map](#)




Brady
 (NYSE:BRC)
 is a
 manufacturer
 of complete
 solutions
 that
 identify and
 protect
 people,
 products
 and places.
 Brady's
 products
 help
 customers
 increase
 safety,
 security,
 productivity
 and
 performance
 and include
 high-
 performance
 labels,
 signs, safety
 devices,
 printing
 systems
 and
 software.

Contact
 6555
 W.
 Good
 Hope
 Rd.
 Milwaukee
 WI
 53223
 Phone:
 888-
 250-
 3082
 Hours:
 7am-
 6pm
 CST
 Monday
 -
 Thursday:
 Friday
 7am-
 5pm
 CST

About
[Corporation](#)
[Privacy](#)
[Policy](#)
[Terms](#)
 and
[Conditions](#)
[Terms](#)
 of Use
[ISO](#)
[Certificates](#)

Other
[Brady](#)
[Sites](#)
[Distributor](#)
[Portal](#)
[International](#)
[Sites](#)
[Safety](#)
[Services](#)
 &
[Software](#)
[Smart](#)
[ID](#)
[Brand](#)
[Protection](#)

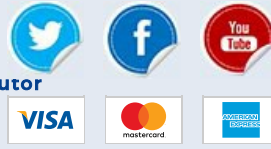

© 2018 Brady Worldwide, Inc.