




SEARCH

[Labels](#) / [Labels by Application](#) / [Inspection and Inventory Labels](#) / [Inspection Repair Labels](#) /

Write-on Labels

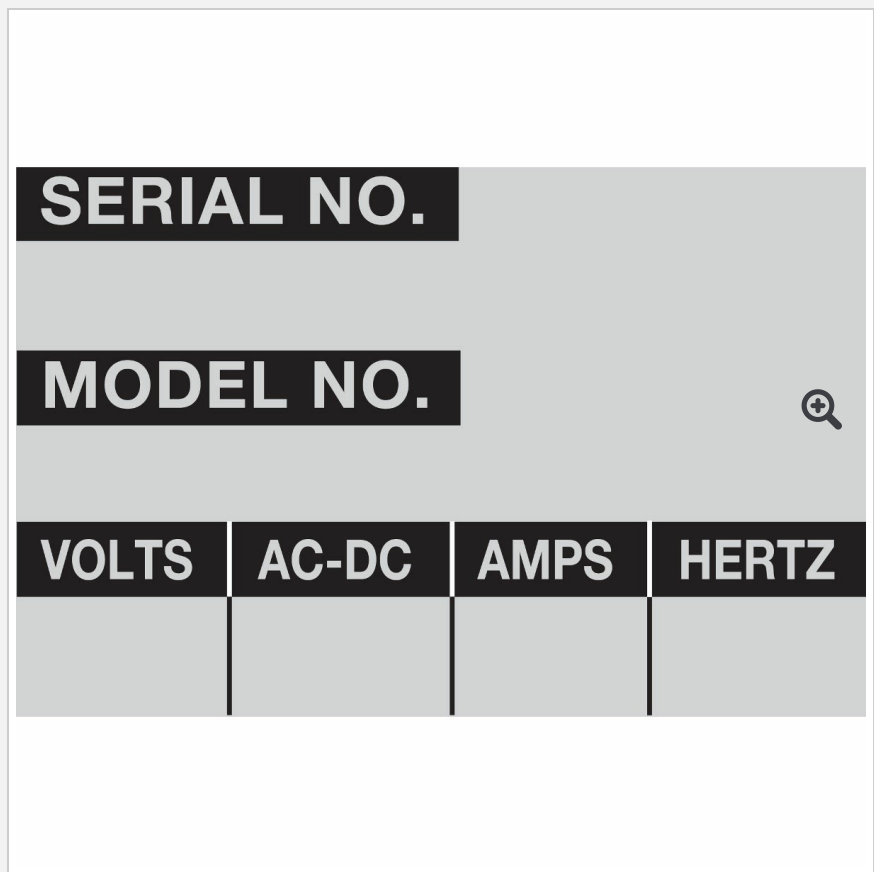

Write-on Labels

Part Number:

WOAF-36

Dimensions:

2.25 in H x 1 in W

Material:

Aluminum Foil

Color:

Black on Silver

ADD TO CART

1



[Add To Favorites](#)

PEOPLE ALSO VIEWED

OVERVIEW

These dead soft aluminum foil (B-184) labels are resistant to heat, oil and solvents.

- The B-184 material has excellent conformability
- Dot matrix printable or can be written on
- Silver finish gives them a permanent debossed appearance
- RoHS Compatibility Pass 2011/65/EU

SPECIFICATIONS

Material Number	B-184
Dimensions	2.25 in H x 1 in W
UOM	Card of 6 Labels
Finish	Matte
Maximum Service Temperature °F	266 °F
Minimum Service Temperature °F	-40 °F
Product Number	35136
UPC	662820351368
Quantity per Card or Sheet	6
Thickness	0.0046 in
Write-On	Yes
Write-On Area?	Yes
Adhesive Type	Acrylic
Color	Black on Silver
Header	No Header
Label Properties	Permanent Adhesive Labels
Language	English

Material	Aluminum Foil
Material Properties	Metallic Appearance
Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Corrosion-Resistant, Heat-Resistant, Humidity-Resistant, Oil-Resistant, UV-Resistant, Weather-Resistant
Text Legend	SERIAL NO. MODEL NO. VOLTS AC-DC AMPS HERTZ

Solutions

[Floor Marking Guide](#)
[GHS Label Compliance](#)
[Lockout Tagout Compliance](#)
[Arc Flash Labeling Requirements](#)
[Cable and Wire Label Options](#)
[Product and Barcode Labeling](#)
[Brand Protection Solutions](#)

Services

[Lockout Tagout Services](#)
[Arc Flash Services](#)
[Confined Space Services](#)
[Visual Workplace Services](#)
[Hazcom GHS Services](#)
[Software Programming & Integration](#)
[Label Template & File Conversion](#)
[Printer Use & Training](#)
[Printer Preventative Maintenance](#)
[Toll and Custom Coating](#)
[Authentication & Tracking Services](#)

Help

[Contact Us](#)
[Knowledge Center](#)
[Printer Drivers & Firmware](#)
[Brady Software Updates](#)
[Safety Data Sheets](#)
[Technical Data Sheets](#)
[WEEE-RoHS Compliance](#)
[Product Certification](#)
[Printer Registration](#)

Resources

[Find a Distributor](#)
[Design Custom Safety Signs](#)
[Printer Selection Tool](#)
[Label Selection Tool](#)
[Digital Catalog](#)
[Request a Catalog](#)
[Interactive Facility Map](#)
[EPA e-Manifest Update](#)

Corporate


[About](#)
[Careers](#)
[Investors](#)
[Privacy Policy](#)
[Terms and Conditions](#)
[Terms of Use](#)
[ISO Certificates](#)

Other BradyContact Sites

[Distributor Portal](#)
[International Sites](#)
[Safety Services & Software](#)
[Smart ID Brand Protection Solutions](#)

6555 W. Good Hope Rd.
 Milwaukee, WI 53223
 Phone: 888-250-3082
 Hours: 7am-6pm CT
 Monday - Thursday;
 Friday 7am-5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

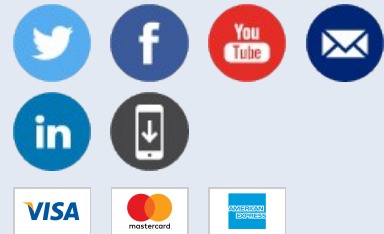

2018 © Brady Worldwide, Inc.