


Printer Labels / Bradyprinter PR Plus Printer Labels /  
3" Core Double Sided PermaSleeve Polyolefin Wire Marking Sleeves

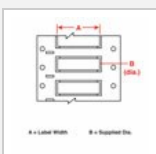

# 3" Core Double Sided PermaSleeve Polyolefin Wire Marking Sleeves

**Part Number:**

3PS-750-2-WT-S

**Material:**

Polyolefin

**For Use with Printer:**

BRADY IP® Series Label Printer,  
BradyPrinter i5100, BradyPrinter i7100,  
BRADYPRINTER PR Plus Series Label Printer

**Material Number:**

B-342

**Color:**

White

**Quantity per Roll:**

100

[ADD TO CART](#)

1



[Add To Favorites](#)

## OVERVIEW

PermaSleeve® PS Heat-Shrink Polyolefin (B-342) wire marking sleeves combine speed, ease of use, and permanence to create long-lasting, high quality identification.

- 3:1 heat shrinkable sleeve fit snugly around wires for maximum insulation protection and permanent identification
- Fade-resistant and smudge-proof for superior aesthetic appearance
- Cold resistant and flame-retardant with an operating temperature of -67°F to 275°F (-55°C to 135°C)
- Meets SAE-AMS-DTL-23053/5C (Class 1), SAE-AS-81531, MIL-STD-202; RoHS Compliant; and UL Recognized

# SPECIFICATIONS

Material Number	<b>B-342</b>
Diameter as Supplied	0.75 in
Dimensions	1.25 in H
UOM	Roll
Finish	Matte
Maximum Service Temperature °F	275 °F
Maximum Wire Diameter	0.7 in
Maximum Wire Gauge	4/0 AWG
Minimum Service Temperature °F	-67 °F
Minimum Wire Diameter	0.25 in
Minimum Wire Gauge	6 AWG
Printable Sides	Double-Side Printable
Product Number	110396
UPC	662820898795
Quantity per Roll	100
Quantity per Row	1
Recovered Diameter	0.25 in
Roll Width	2 in
Shrink Ratio	3:1
Sleeve Size	0.75 in Dia x 2 in W
Sleeve Size(m)	19.1 mm Dia x 50.8 mm W
Sleeve Width	2 in
Applications	Cable & Wire Marking
Color	White
For Use with Printer	BRADY IP® Series Label Printer, BradyPrinter i5100, BradyPrinter i7100, BRADYPRINTER PR Plus Series Label Printer
Label/Media Format	Roll
Label Properties	Heat Shrink Sleeves
Material	Polyolefin
Material Properties	Flame-retardant, Heat-Shrinkable
Print Technology	Thermal Transfer
Resistance Properties	Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, Smear-Resistant, UV-Resistant, Weather-Resistant
Suggested Ribbon Series	R2000, R4300, R4502S, R5000, R6600, R6700

## Solutions

Floor Marking Guide  
GHS Label Compliance  
Lockout Tagout Compliance  
Arc Flash Labeling Requirements  
Cable and Wire Label Options  
Product and Barcode Labeling  
Brand Protection Solutions

## Services

Lockout Tagout Services  
Arc Flash Services  
Confined Space Services  
Visual Workplace Services  
Hazcom GHS Services  
Software Programming & Integration  
Label Template & File Conversion  
Printer Use & Training  
Printer Preventative Maintenance  
Toll and Custom Coating  
Authentication & Tracking Services

## Help

Contact Us  
Knowledge Center  
Printer Drivers & Firmware  
Brady Software Updates  
Safety Data Sheets  
Technical Data Sheets  
WEEE-RoHS Compliance  
Product Certification  
Printer Registration

## Resources

Find a Distributor  
Design Custom Safety Signs  
Printer Selection Tool  
Label Selection Tool  
Digital Catalog  
Request a Catalog  
Interactive Facility Map  
EPA e-Manifest Update



### Corporate


[About](#)  
[Careers](#)  
[Investors](#)  
[Privacy Policy](#)  
[Terms and Conditions](#)  
[Terms of Use](#)  
[ISO Certificates](#)

### Other BradyContact Sites

[Distributor Portal](#)  
[International Sites](#)  
[Safety Services & Software](#)  
[Smart ID Brand Protection Solutions](#)

6555 W. Good Hope Rd.  
Milwaukee, WI 53223  
Phone: 888-250-3082  
Hours: 7am-6pm CT  
Monday - Thursday;  
Friday 7am-5pm CT

**Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.**

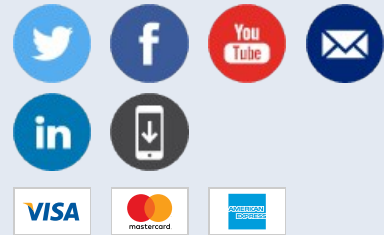

2018 © Brady Worldwide, Inc.