
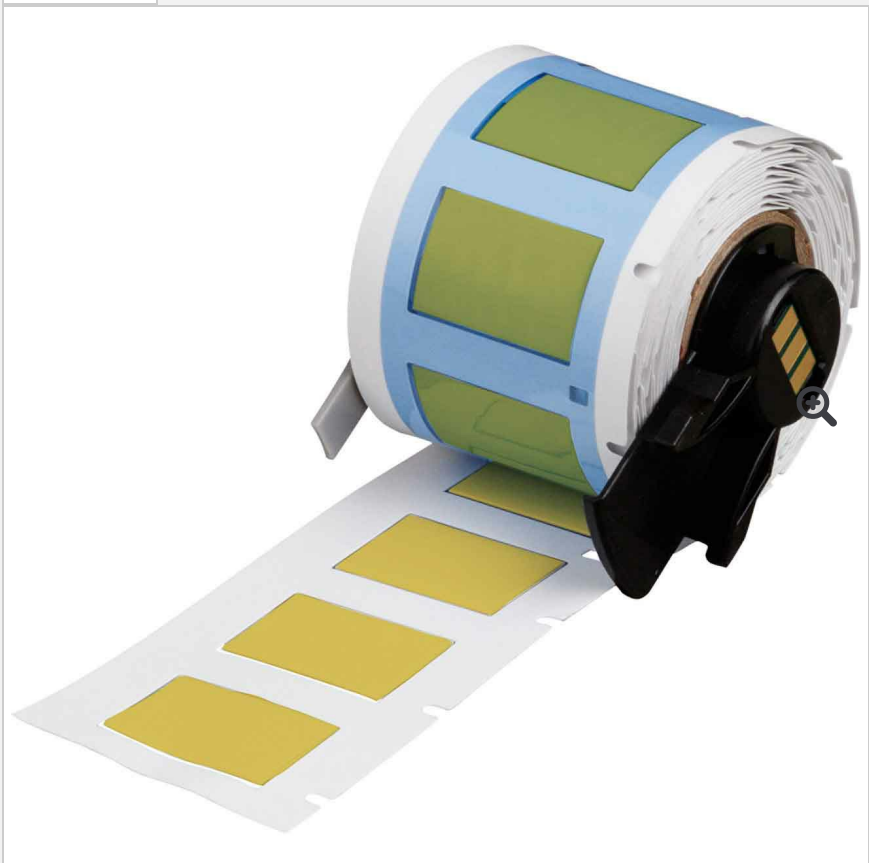


[Labels](#) / [Labels by Portable Printer](#) / [TLS PC Link Labels](#) /

BMP61 BMP71 TLS 2200 PermaSleeve Polyolefin Wire Marking Sleeves

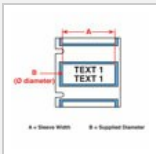

BMP61 BMP71 TLS 2200 PermaSleeve Polyolefin Wire Marking Sleeves

Part Number:

PSPT-375-1-YL

Material:

Polyolefin

For Use with Printer:

BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System

Color:

Yellow

Material Number:

B-342

ADD TO CART

1



[Add To Favorites](#)

PEOPLE ALSO VIEWED

OVERVIEW

PermaSleeve® PS Heat-Shrink Polyolefin (B-342) wire marking sleeves combine speed, ease of use, and permanence to create long-lasting, high quality identification.

- 3:1 heat shrinkable sleeve fit snugly around wires for maximum insulation protection and permanent identification
- Fade-resistant and smudge-proof for superior aesthetic appearance
- Cold resistant and flame-retardant with an operating temperature of -67°F to 275°F (-55°C to 135°C)
- Meets SAE-AMS-DTL-23053/5C (Class 1), SAE-AS-81531, MIL-STD-202; RoHS Compliant; and UL Recognized

SPECIFICATIONS

Material Number	B-342
Diameter as Supplied	0.375 in
Dimensions	0.645 in H x 1.1677 in W
UOM	Roll
Finish	Matte
Maximum Service Temperature °F	275 °F
Maximum Wire Diameter	0.32 in
Maximum Wire Gauge	6 AWG
Minimum Service Temperature °F	-67 °F
Minimum Wire Diameter	0.125 in
Minimum Wire Gauge	12 AWG
Printable Sides	Single-Side Printable
Product Number	18484
UPC	662820184843
Quantity per Roll	100
Quantity per Row	1
Recovered Diameter	0.125 in
Roll Width	1 in
Shrink Ratio	3:1
Sleeve Size	0.375 in Dia x 1 in W
Sleeve Size(m)	9.5 mm Dia x 25.4 mm W
Sleeve Width	1 in
Applications	Cable & Wire Marking, Panel Labeling
Color	Yellow
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Label/Media Format	Roll
Label Properties	Heat Shrink Sleeves
Material	Polyolefin
Material Properties	Flame-retardant, Heat-Shrinkable
Print Technology	Thermal Transfer

Resistance Properties	Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, Smear-Resistant, UV-Resistant, Weather-Resistant
Suggested Ribbon Series	R4300, R4502S, R5000, R6600, R6700

Solutions

[Floor Marking Guide](#)
[GHS Label Compliance](#)
[Lockout Tagout Compliance](#)
[Arc Flash Labeling Requirements](#)
[Cable and Wire Label Options](#)
[Product and Barcode Labeling](#)
[Brand Protection Solutions](#)

Services

[Lockout Tagout Services](#)
[Arc Flash Services](#)
[Confined Space Services](#)
[Visual Workplace Services](#)
[Hazcom GHS Services](#)
[Software Programming & Integration](#)
[Label Template & File Conversion](#)
[Printer Use & Training](#)
[Printer Preventative Maintenance](#)
[Toll and Custom Coating](#)
[Authentication & Tracking Services](#)

Help

[Contact Us](#)
[Knowledge Center](#)
[Printer Drivers & Firmware](#)
[Brady Software Updates](#)
[Safety Data Sheets](#)
[Technical Data Sheets](#)
[WEEE-RoHS Compliance](#)
[Product Certification](#)
[Printer Registration](#)

Resources


[Find a Distributor](#)
[Design Custom Safety Signs](#)
[Printer Selection Tool](#)
[Label Selection Tool](#)
[Digital Catalog](#)
[Request a Catalog](#)
[Interactive Facility Map](#)
[EPA e-Manifest Update](#)

Corporate
[About](#)
[Careers](#)
[Investors](#)
[Privacy Policy](#)
[Terms and Conditions](#)
[Terms of Use](#)
[ISO Certificates](#)

Other Brady Sites
[Distributor Portal](#)
[International Sites](#)
[Safety Services & Software](#)
[Smart ID Brand Protection Solutions](#)

Contact
 6555 W. Good Hope Rd.
 Milwaukee, WI 53223
 Phone: 888-250-3082
 Hours: 7am-6pm CT
 Monday - Thursday;
 Friday 7am-5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

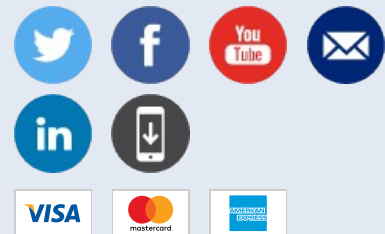

2018 © Brady Worldwide, Inc.