

[Labels](#) / [Labels by Application](#) / [Circuit Board Labels](#) / [Not for Wash Polyester Labels](#) /  
BMP61 M611 TLS 2200 WorkHorse Static Dissipative Glossy Polyester Labels

# BMP61 M611 TLS 2200 WorkHorse Static Dissipative Glossy Polyester Labels



## Product Highlights

**Label/Tape Size:**

0.275 in H x 0.5 in W

**Material:**

Polyester

**For Use with Printer:**

BMP®61 Labeling System, BMP®71 Label Printer, BradyPrinter™ M611, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System

**Label Properties:**

Harsh Environment Labels, Heat Resistant Labels, Permanent Adhesive Labels

**Material Number:**

B-473


**Color:**

White

**Part Number:**


PTL-6-473

**ADD TO CART** 1

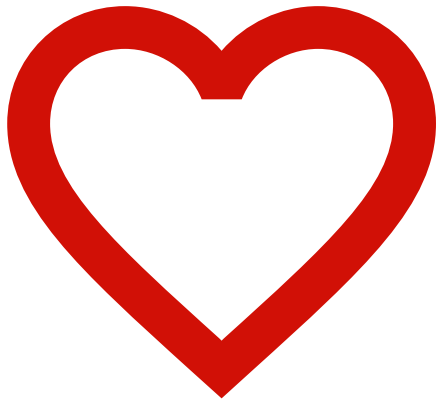

**Add To Favorites**

People Also Viewed

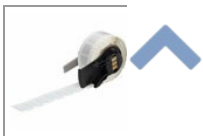

**Overview**

Printable, static dissipative polyester labels for thermal transfer printers.

- Ideal for use in printed circuit board and electronic component post-process labeling
- Abrasive resistant
- Service temperature of -40° F to 248° F

## Specifications

Material Number	<b>B-473</b>
Country of Origin	MX - All trade information (i.e. Country of Origin, Harmonized Schedule code, and/or Export Control Classification Number) and related assistance provided by Brady Corporation and its affiliates is provided for informational purposes only and is subject to change without notice. Any use of such information by you is without recourse to Brady Corporation or its affiliates and is at your own risk. This information is not provided as legal advice or as a substitute for obtaining specific legal advice. If you have any questions regarding your specific situation, you should consult your attorney.
California Prop 65	<b>WARNING:</b> Cancer - <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>
Catalog Page #	350
Dimensions	0.275 in H x 0.5 in W
UOM	Roll of 750 Labels
Finish	Gloss
Label/Tape Size	0.275 in H x 0.5 in W
Maximum Service Temperature °F	248 °F
Minimum Service Temperature °F	-40 °F
Pre-Printed Areas on Label	Colored Write-On Area
Printable Area Dimensions	0.275 in H x 0.5 in W
Printable Area Height	0.275 in
Printable Area Width	0.5 in
Product Number	18325
UPC	662820183259
Quantity per Roll	750
Quantity per Row	1
Thickness	0.0034 in
Trade Name	BMP®61 BMP®71 TLS 2200® TLS-PC Link™ WorkHorse®
Unit Price	/Label
UNSPSC	55121612
Adhesive Type	Acrylic
Applications	Circuit Board ID - After Process, Circuit Board ID - Through Hole Top, General & Industrial ID

Color	White
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, BradyPrinter™ M611, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Header	No Header
Label/Media Format	Roll
Label Properties	Harsh Environment Labels, Heat Resistant Labels, Permanent Adhesive Labels
Language	No Text
Material	Polyester
Material Properties	Static-dissipative
Printer and Label Applications	Circuit Board
Print Technology	Thermal Transfer
Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, UV-Resistant, Weather-Resistant
Shape	Rectangle
Suggested Ribbon Series	R6000

## Solutions

[Floor Marking Guide](#)  
[GHS Label Compliance](#)  
[Lockout Tagout Compliance](#)  
[Arc Flash Labeling Requirements](#)  
[Cable and Wire Label Options](#)  
[Product and Barcode Labeling](#)

## Services

[Lockout Tagout Services](#)  
[Arc Flash Services](#)  
[Confined Space Services](#)  
[Software Programming & Integration](#)  
[Label Template & File Conversion](#)  
[Printer Use & Training](#)  
[Printer Preventative Maintenance](#)  
[Toll and Custom Coating](#)  
[Authentication & Tracking Services](#)

## Help

[Contact Us](#)  
[Website Feedback](#)  
[Knowledge Center](#)  
[Printer Drivers & Firmware](#)  
[Brady Software Updates](#)  
[Safety Data Sheets](#)  
[Technical Data Sheets](#)  
[WEEE-RoHS Compliance](#)  
[Product Certification](#)  
[Printer Registration](#)

## Resources

[Find a Distributor](#)  
[Design Custom Safety Signs](#)  
[Create Custom THT Labels](#)  
[Printer Selection Tool](#)  
[Label Selection Tool](#)  
[Digital Catalog](#)  
[Request a Catalog](#)  
[Interactive Facility Map](#)  
[EPA e-Manifest Update](#)

[About](#)  
[Careers](#)  
[Investors](#)  
[Privacy Policy](#)  
[Terms and Conditions](#)  
[Terms of Use](#)  
[ISO Certificates](#)

[Sites](#)  
[Distributor Portal](#)  
[International Sites](#)  
[Safety Services & Software](#)  
[Brand Protection Solutions](#)

6555 W. Good Hope Rd.  
Milwaukee, WI 53223  
Phone: 888-250-3082  
Hours: 7am-6pm CT  
Monday - Thursday;  
Friday 7am-5pm CT

manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.



2019 © Brady Worldwide, Inc.