


 All Categories


0 item(s) | \$0.00

Products | Standards and Compliance | Customer Support | Technical Support

Home > Labels and Tapes > Labels > Product ID Labels > Barcode and Tracking Labels > Asset Tracking Labels >



Zoom

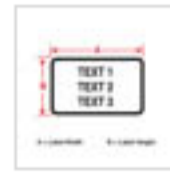

TLS 2200®/TLS PC Link® Labels

Part Number: PTL-24-486-BK

Product Number: 18720

Material Description: Ultra Aggressive Metallized Polyester

QTY/UOM: 500/Roll

Overview

Specifications

Specifications for TLS 2200®/TLS PC Link® Labels

Part Number	PTL-24-486-BK
Adhesive	Permanent Rubber Based
Agency Approval(s)/Compliance	UL Recognized, CSA Approved
Application	Asset Tracking, Rating Plates, General Purpose ID
Brady Material Number	B-486
Brand	MetaLabel Series
Color	Light Gray
Description	TLS 2200®/TLS PC Link® Labels
Finish	Matte
Height (in)	0.500"
Height (mm)	12.700 mm
Label Type/Style	Label
Material Description	Ultra Aggressive Metallized Polyester
Material Type	Polyester
Max Characters Per Line For Font #2	24
Max Lines of Text For Font #2	3
Panel Application	General Identification
Printable Area (in)	1.130" W x 0.500" H
Printable Area (mm)	28.700 mm W x 12.700 mm H
Printer Compatibility	TLS 2200, TLS-PC Link, BMP71
Product Number	18720
Qty Per Row	1
QTY/UOM	500/Roll
Recommended Ribbon Series	R4310
Safety Catalog	pg. 314
Special Properties	Ultra-aggressive adhesive, Designed for powder coated surfaces
Suggested Ribbon Part#	R4310
Surface	Smooth, Textured/Rough, Highly Textured, Low Surface Energy
Surface Mount Technology (SMT)	No, this material does not work with this application
Through Hole Technology	No, this material does not work with this application
UPC Code	66282018720
Width (in)	1.130"
Width (mm)	28.700 mm
RoHS Compatibility	Pass 2011/65/EU

CONTACT

Contact Us
Email Subscription
International Sites

ABOUT

Company Information
News & Events

CORPORATE INFORMATION

Privacy Policy
Terms of Use

SOCIAL

Facebook
Twitter
YouTube

