


 All Categories


0 item(s) | \$0.00

Products | Standards and Compliance | Customer Support | Technical Support

Home > Labels and Tapes > Labels > Product ID Labels > Barcode and Tracking Labels > Asset Tracking Labels >



Zoom

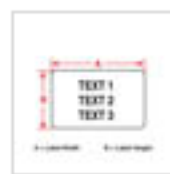

TLS 2200®/TLS PC Link® Thermal Transfer Portable Printer Labels

Part Number: PTL-5-423
Product Number: 18320
Material Description: Permanent Polyester
QTY/UOM: 750/Roll

Overview | Specifications

Specifications for TLS 2200®/TLS PC Link® Thermal Transfer Portable Printer Labels

Part Number	PTL-5-423
Acceptable Ribbon Series	R6210, R4410 (colors)
Adhesive	Permanent Acrylic
After Process	Yes, this material will work with this application
Agency Approval(s)/Compliance	UL Recognized, CSA Approved, AGA Approved, Halogen-Free (DIN VDE 0472/parts 815)
Application	Component ID, Equipment ID, Barcoding, Asset Tracking, Rating Plates, General Purpose ID
Board Application	Through Hole - Top
Brady Material Number	B-423
Brand	WorkHorse Series
Color	White
Description	TLS 2200®/TLS PC Link® Thermal Transfer Portable Printer Labels
Finish	Gloss
Height (in)	0.200"
Height (mm)	5.080 mm
Label Type/Style	Label
Material Description	Permanent Polyester
Material Type	Polyester
Max Characters Per Line For Font #2	11
Max Lines of Text For Font #2	1
Panel Application	General Identification
Printable Area (in)	0.500" W x 0.200" H
Printable Area (mm)	12.700 mm W x 5.080 mm H
Printer Compatibility	TLS 2200, TLS-PC Link, BMP71
Product Number	18320
Qty Per Row	1
QTY/UOM	750/Roll
Recommended Ribbon Series	R6010
Safety Catalog	pg. 312
Suggested Ribbon Part#	R6010
Surface	Smooth
Through Hole Technology	No, this material does not work with this application
UPC Code	66282018320
Width (in)	0.500"
Width (mm)	12.700 mm
RoHS Compatibility	Pass 2011/65/EU

CONTACT
 Contact Us
 Email Subscription
 International Sites

ABOUT
 Company Information
 News & Events

CORPORATE INFORMATION
 Privacy Policy
 Terms of Use

SOCIAL
 Facebook
 Twitter
 YouTube

