

General Labels/Rating Plates

Choose from several materials with aggressive adhesives for use in commercial/industrial applications.

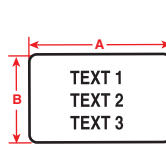


Figure 4

 


Figure 8

 


Figure 14



Die Cut Labels

Diagram	Part Number	Labels/Roll	Material	Color	A Inch	Label Dimensions (mm)	B Inch	Recommended (mm)	Ribbon
Fig. 4	M71-68-430	750	B-430	Clear	0.240	(6.000)	0.150	(3.810)	M71-R6000
Fig. 4	M71-71-430	750	B-430	Clear	0.350	(8.890)	0.200	(5.080)	M71-R6000
Fig. 14	M71-80-488	250	B-488	White	0.750	(19.050)	0.900	(22.860)	M71-R4300
Fig. 4	M71-97-488	250	B-488	White	0.900	(22.860)	0.900	(22.860)	M71-R4300
Fig. 4	M71-16-430	500	B-430	Clear	1.000	(25.400)	0.375	(9.530)	M71-R6000
Fig. 4	M71-17-430	500	B-430	Clear	1.000	(25.400)	0.500	(12.700)	M71-R6000
Fig. 4	M71-16-483	500	B-483	White	1.000	(25.400)	0.375	(9.530)	M71-R6000
Fig. 4	M71-17-483	500	B-483	White	1.000	(25.400)	0.500	(12.700)	M71-R6000
Fig. 4	M71-19-483	250	B-483	White	1.000	(25.400)	1.000	(25.400)	M71-R6000
Fig. 4	M71-17-486	500	B-486	Silver	1.000	(25.400)	0.500	(12.700)	M71-R4300
Fig. 4	M71-45-430	500	B-430	Clear	1.050	(38.100)	0.375	(9.530)	M71-R6000
Fig. 4	M71-65-483	250	B-483	White	1.375	(34.930)	1.000	(25.400)	M71-R6000
Fig. 4	M71-29-459	500	B-459	White	1.500	(38.100)	0.500	(12.700)	M71-R6000
Fig. 4	M71-30-459	250	B-459	White	1.500	(38.100)	0.750	(19.050)	M71-R6000
Fig. 4	M71-29-483	500	B-483	White	1.500	(38.100)	0.500	(12.700)	M71-R6000
Fig. 4	M71-30-483	250	B-483	White	1.500	(38.100)	0.750	(19.050)	M71-R6000
Fig. 4	M71-31-483	250	B-483	White	1.500	(38.100)	1.000	(25.400)	M71-R6000
Fig. 4	M71-29-486	500	B-486	Silver	1.500	(38.100)	0.500	(12.700)	M71-R4300
Fig. 4	M71-30-486	250	B-486	Silver	1.500	(38.100)	0.750	(19.050)	M71-R4300
Fig. 4	M71-29-489	500	B-489	White	1.500	(38.100)	0.500	(12.700)	M71-R4300
Fig. 4	M71-32-489	250	B-489	White	1.500	(38.100)	1.500	(38.100)	M71-R4300
Fig. 4	M71-81-488	750	B-488	White	1.900	(48.260)	0.250	(6.350)	M71-R4300
Fig. 4	M71-20-459	100	B-459	White	2.000	(50.800)	1.000	(25.400)	M71-R6000
Fig. 4	M71-61-483	100	B-483	White	2.000	(50.800)	0.500	(12.700)	M71-R6000
Fig. 4	M71-20-483	100	B-483	White	2.000	(50.800)	1.000	(25.400)	M71-R6000
Fig. 4	M71-20-486	100	B-486	Silver	2.000	(50.800)	1.000	(25.400)	M71-R4300
Fig. 4	M71-37-483	100	B-483	White	3.000	(76.200)	1.900	(48.260)	M71-R6000
Fig. 4	M71-37-486	100	B-486	Silver	3.000	(76.200)	1.900	(48.260)	M71-R4300
Fig. 4	M71-23-483	100	B-483	White	4.000	(101.600)	1.000	(25.400)	M71-R6000
Fig. 4	M71-38-483	100	B-483	White	4.000	(101.600)	1.900	(48.260)	M71-R6000
Fig. 4	M71-38-489	100	B-489	White	4.000	(101.600)	1.900	(48.260)	M71-R4300

Specialty Continuous Tape

Diagram	Part Number	Labels/Roll	Material	Color	A Inch	Label Dimensions (mm)	B Inch	(mm)	Recommended Ribbon
Fig. 8	M71C-375-430	1 Roll (cont.)	B-430	Clear	0.375	(9.530)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-500-430	1 Roll (cont.)	B-430	Clear	0.500	(12.700)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-500-483	1 Roll (cont.)	B-483	White	0.500	(12.700)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-1000-430	1 Roll (cont.)	B-430	Clear	1.000	(25.400)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-1000-483	1 Roll (cont.)	B-483	White	1.000	(25.400)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-1900-430	1 Roll (cont.)	B-430	Clear	1.900	(48.260)	50 ft.	(15.24 m)	M71-R6000
Fig. 8	M71C-1900-483	1 Roll (cont.)	B-483	White	1.900	(48.260)	50 ft.	(15.24 m)	M71-R6000

See all ribbon colors on page 115.

