

EM2565 Series**EuroMag Terminal Blocks**

Pluggable Block (Mates with EM2575 Series); 5.08 Centers

SPECIFICATIONS

Rating: 16A, 300V

Center Spacing: 0.20" (5.08mm)

Consult factory for 0.40" (10.16mm)

Wire Range: #12-24 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Screw Size: M3.0 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

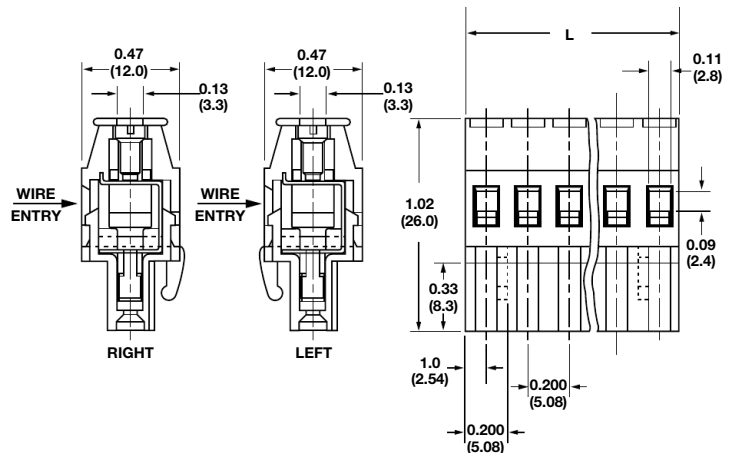
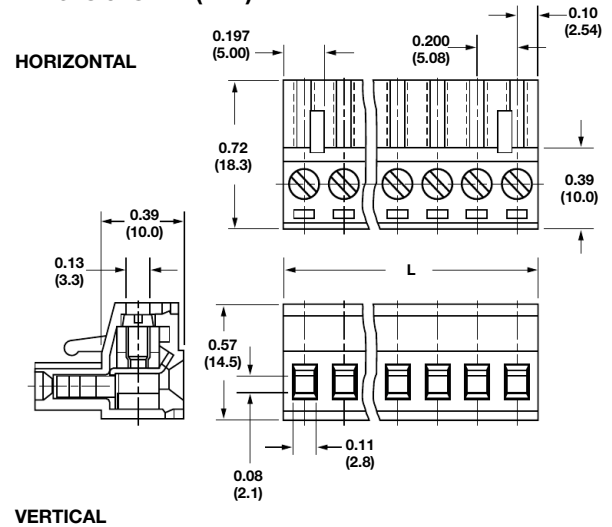
Torque Rating: 7 lb-in.

Construction: Mold-to-Length

Agency Information: e•RA US File E62622; CE Certified



EM256503H

Dimensions - in (mm)

To convert to inches, divide by 25.4

Part Numbering System

Series	# of Positions	Orientation	Wire Entry (Vertical Orientation Only)	Mating Header: EM2575 pg. 92
EM2565				
	02 to 24	H - horizontal V - vertical	L - left R - right	