


PART
NAME


VALURACK

PART
No.


VR-8924, VR-8925 AND VR-8926

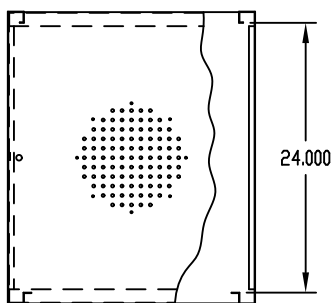


TOP VIEW

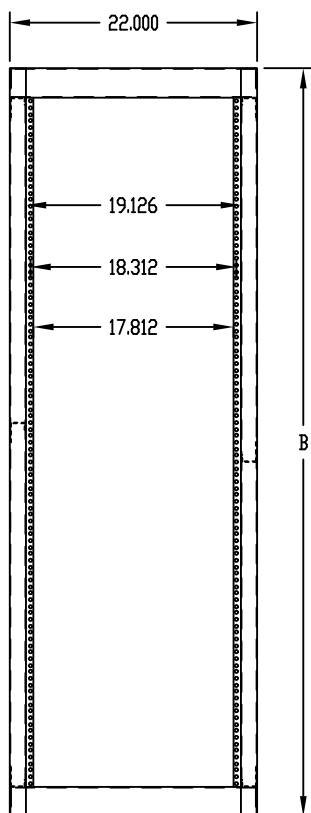


FRONT VIEW

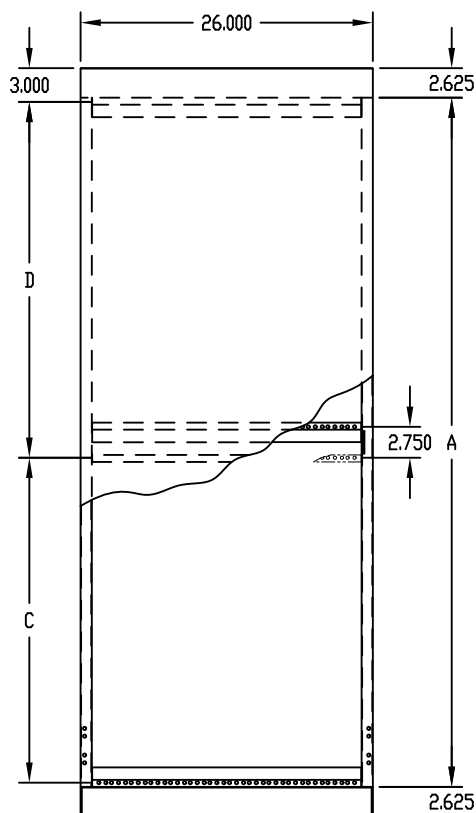

RIGHT SIDE VIEW

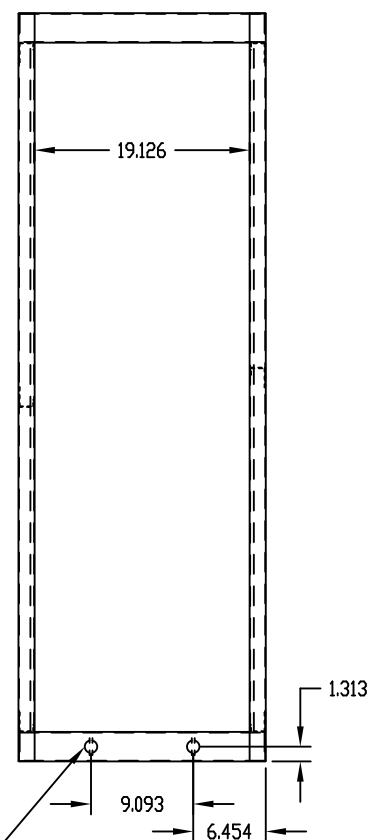

REAR VIEW

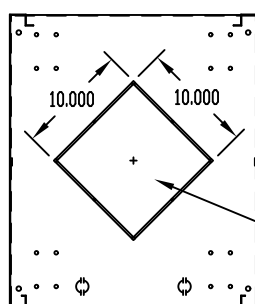

BOTTOM VIEW

KNOCKOUT

Ø1.109 KNOCKOUT
(4 PLCS)**NOTES:**

INTEGRAL PANEL MOUNTING RAILS ARE PIERCED Ø0.281

HOLES ON E.I.A. UNIVERSAL SPACING.

BOTTOM PIERCED FOR RC-7758 CASTERS OR RL-7766 LEVELERS

FINISH: BLACK TEXTURE

PART No.	A	B	C	D
VR-8924	61.312	66.562	28.906	31.656
VR-8925	70.062	75.312	33.281	36.031
VR-8926	78.812	84.062	37.656	40.406

MATERIAL:SIDES _____ 18 GA. STEEL
TOP, BOTTOM & RAIL SUPPORTS _____ 16 GA. STEEL