

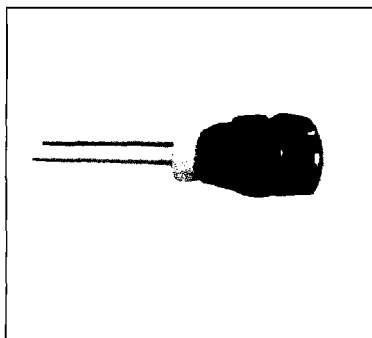
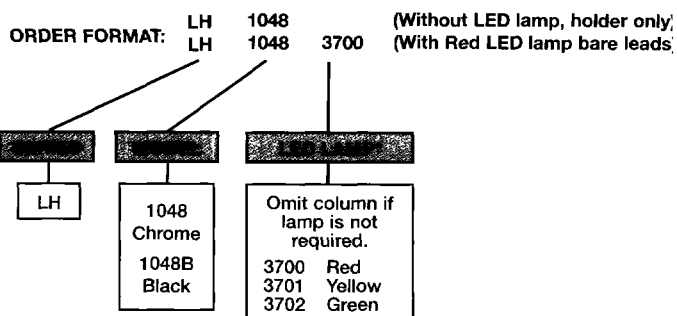



Available with or without LED lamp.
Brass body with Black or Chrome finish.
Panel mtg hole 8.0 (.315)
Panel thickness 5.5 (.216)

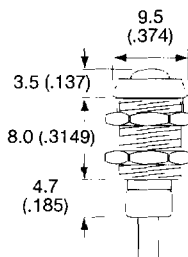

*Lamp specifications see below.


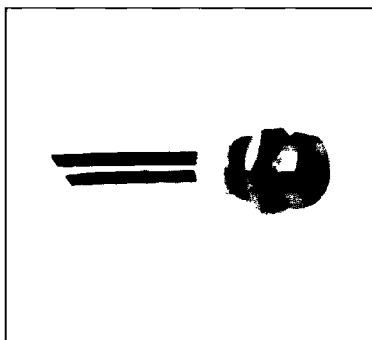


Available with or without LED lamp.
Brass body with Black or Chrome finish.
Panel mtg hole 8.0 (.315)
Panel thickness 5.5 (.216)

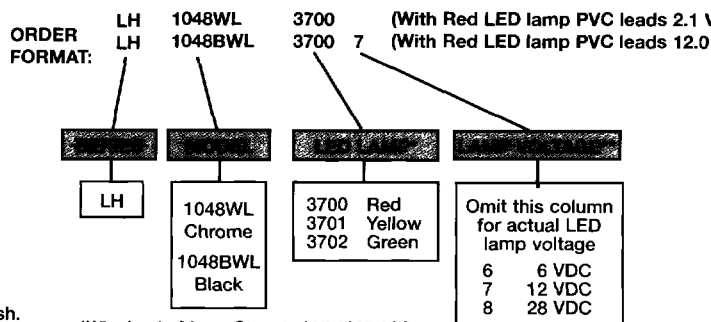


*Wire leads 24awg Stranded UL1007 80C Black and Red 5" min length 1/4" strip. Consult factory for alternative lengths.



**Voltage dropping resistor located inline on Red lead for 6-28V. Lamp specifications bottom of page.

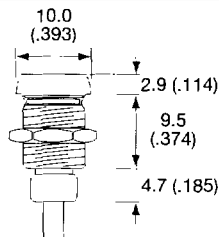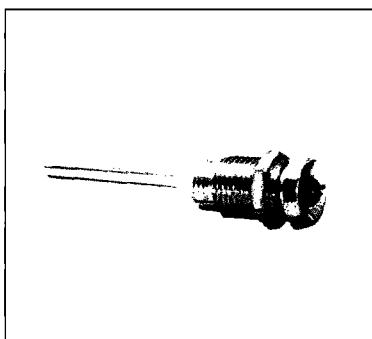


Lamp recessed below bezel.
Available with or without LED lamp.
Brass body with Black or Chrome finish.
Panel mtg hole 8.0 (.315)
Panel thickness 7.0 (.275)

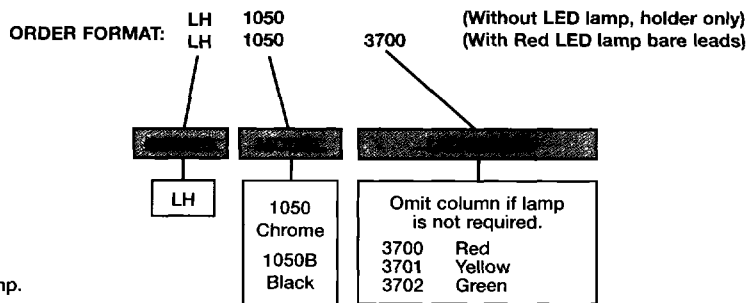

*Lamp specifications bottom of page.

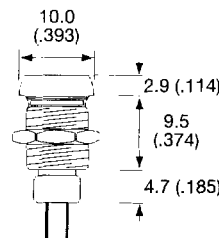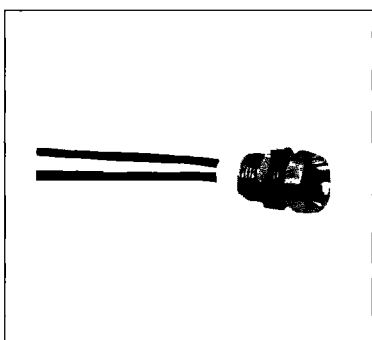

Lamp recessed below bezel.
Available with or without LED lamp.
Brass body with Black or Chrome finish.
Panel mtg hole 8.0 (.315)
Panel thickness 7.0 (.275)

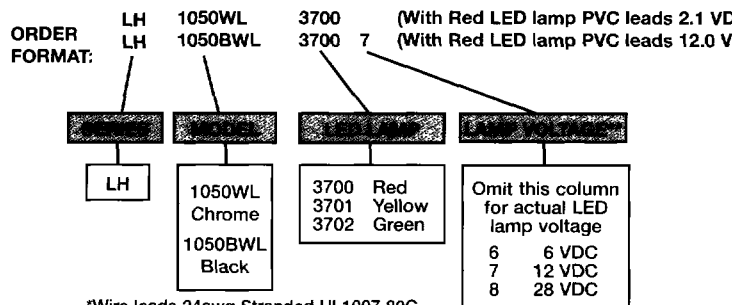

*Wire leads 24awg Stranded UL1007 80C Black and Red 5" min length 1/4" strip. Consult factory for alternative lengths.

**Voltage dropping resistor located inline on Red lead for 6-28V. Lamp specifications bottom of page.

LAMP SPECIFICATIONS

T1.3/4 (5mm)

SUPER BRIGHTNESS DIFFUSED

LAMP	OUTPUT COLOR	PACKAGE COLOR	VIEW DEG	MIN MCD	TYP MCD	RATED ma	VOLT TYP	VOLT MAX	FORWARD CONT ma	PEAK WAVE NM
3700	Red	Red	30	3.0	6.0	10	2.1	2.5	30	700
3701	Yellow	Yellow	30	8.0	16	20	2.2	2.5	50	580
3702	Green	Green	30	5.0	8.0	20	2.1	2.5	50	555