


PX0841/A3/1M00 Datasheet

Product Name // Overmoulded USB 3.0 Cable PX0841
Series USB Sealed A Plug to Sealed A Plug 1m Cable

 [View Product Page](#)

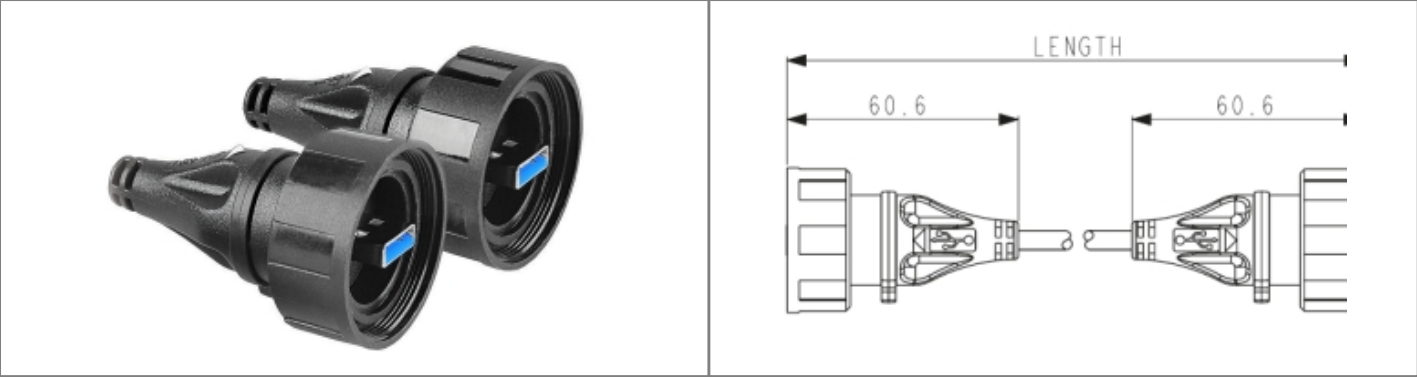

// **Product Description:**

- Pre-Wired Overmoulded USB 3.0 Cable
 - Water and dustproof to IP68 when mated with compatible connector
 - Sealed Standard USB 3.0 Type A plug to Sealed Standard USB 3.0 Type A plug
- 1m Cable Length
 - PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with PX08 Standard USB 3.0 Series Panel Mount Connectors

// **General Information:**

Product Display Title:	Pre-Wired Overmoulded USB 3.0 Cable
Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - USB
Body Colour:	Black
Body Material:	PVC
Cable Length:	1m
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB 3.0 Sealed A Plug to Sealed A Plug
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Flex to Flex Connector Double Ended Cable
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	9 Contacts
Rohs Compliant:	Yes
Voltage Max:	5V

// **Product PDF Links**

 [Standard Series USB connectors...](#)

// **Product 3D CAD Model Links**

 [PX0841/A3/1M003D CAD Model](#)