


PXF6050AAB Datasheet

Product Name // 10 M, OM3 Multi Mode, Cabled, Flex fiber connector

 [View Product Page](#)

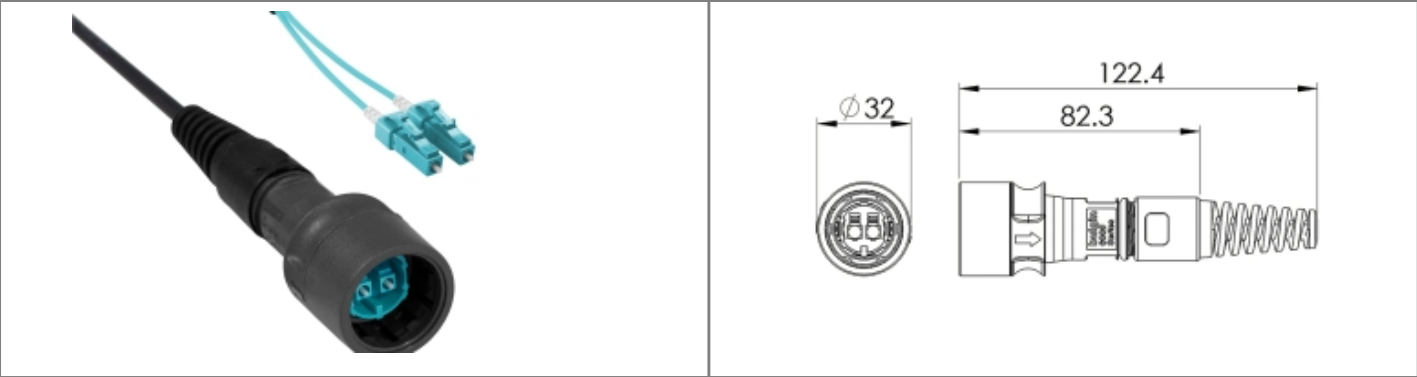

// Product Description:

- Flex Fiber Connector to LC type connector
 - Sealed to IP66, IP68, IP69K when mated with compatible connector
 - no cable options, or pre-terminated from 5M - 450M available
 - Duplex LC type fiber connector
- Choices of OS1, OM1 and OM3 cables for single or multimode
 - PXP6083 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with Inline fiber connector or panel mount connectors PXF6051, PXF6052

// General Information:

Product Display Title:	Flex Fiber Connector to LC type Connector
Product Family:	Circular Fiber Connectors
Product Series:	6000 Series - Duplex LC Fiber Buccaneer
Body Material:	Polyamide (PA)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	32mm
Fibre Mode:	OM3
Flamability Rating:	UL94V-0
Function:	Flex to Double LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-25°C

// Product PDF Links

 [6000 Series Fiber connectors...](#)

// Product 3D CAD Model Links

 [PXF6050AAB3D CAD Model](#)