


PXF6051AAH Datasheet

 [View Product Page](#)

Product Name // 200 M, OM3 Multi Mode, Cabled, Inline fiber connector

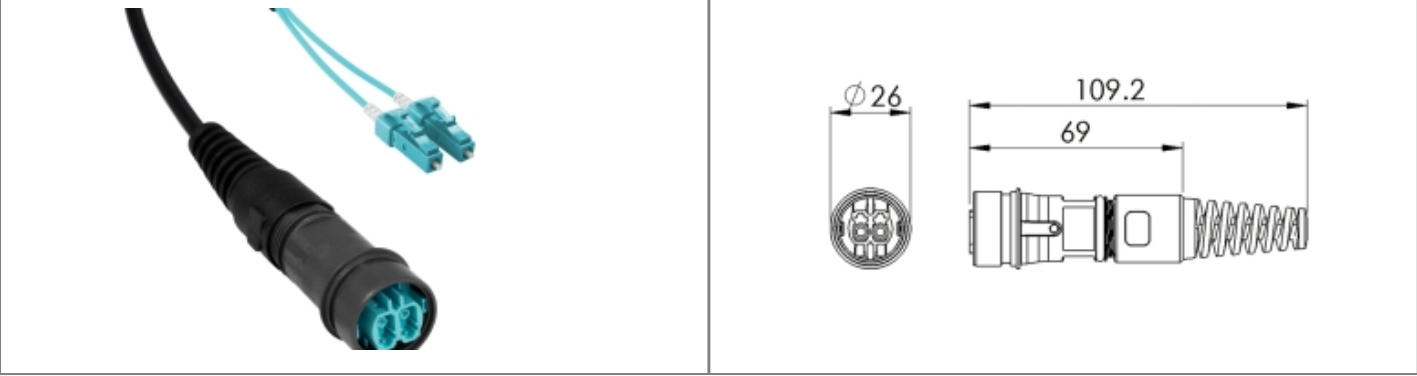

// Product Description:

- Inline Fiber Connector to LC type connector
 - Sealed to IP66, IP68, IP69K when mated with compatible connector
 - no cable options, or pre-terminated from 5M - 450M available
 - Duplex LC type fiber connector
- Choices of OS1, OM1 and OM3 cables for single or multimode
 - PXP6081 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with flex fiber connector PXF6050

// General Information:

Product Display Title:	Inline Fiber Connector to LC type Connector
Product Family:	Circular Fiber Connectors
Product Series:	6000 Series - Duplex LC Fiber Buccaneer
Body Material:	Polyamide (PA)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	32mm
Fibre Mode:	OM3
Flamability Rating:	UL94V-0
Function:	Inline to Double LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-25°C

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)