


PXF6052B Datasheet

 [View Product Page](#)

Product Name // No Cable, Rear panel mount fiber connector for OM1 cable

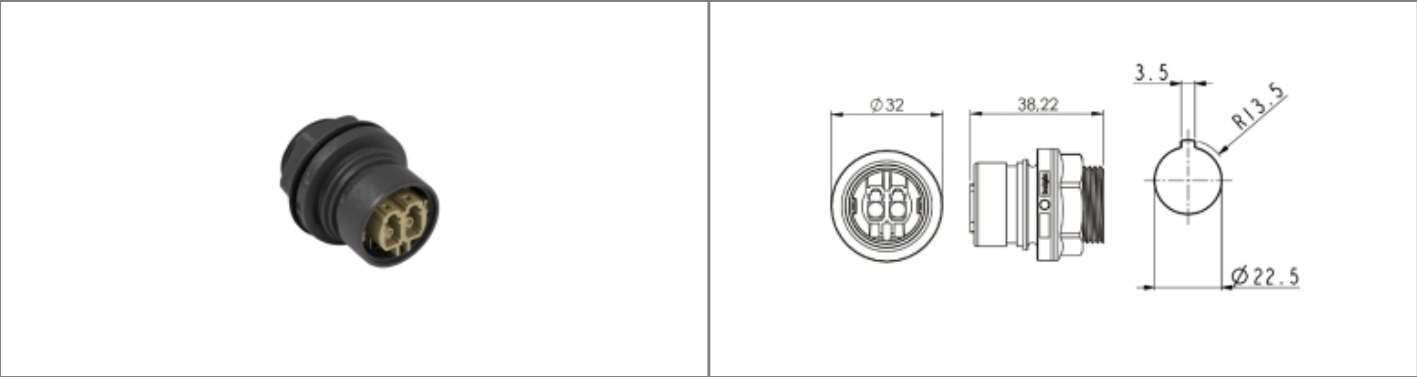

// Product Description:

- Rear Panel Mount Fiber Connector
- Sealed to IP66, IP68, IP69K when mated with compatible connector
- no cable options, or pre-terminated 1M available
- Duplex LC type fiber connector
- Choices of OS1, OM1 and OM3 cables for single or multimode
- PXP6081 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mate with flex fiber connector PXF6050

// General Information:

Product Display Title:	Rear Panel Mount Fiber Connector
Product Family:	Circular Fiber Connectors
Product Series:	6000 Series - Duplex LC Fiber Buccaneer
Body Material:	Polyamide (PA)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	32mm
Fibre Mode:	OM1
Flamability Rating:	UL94V-0
Function:	Rear Panel Mount to Double LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-25°C

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)