


PXF6052CAA Datasheet

Product Name // 01 M, OS1 Single Mode, Cabled, Rear panel mount fiber connector

 [View Product Page](#)

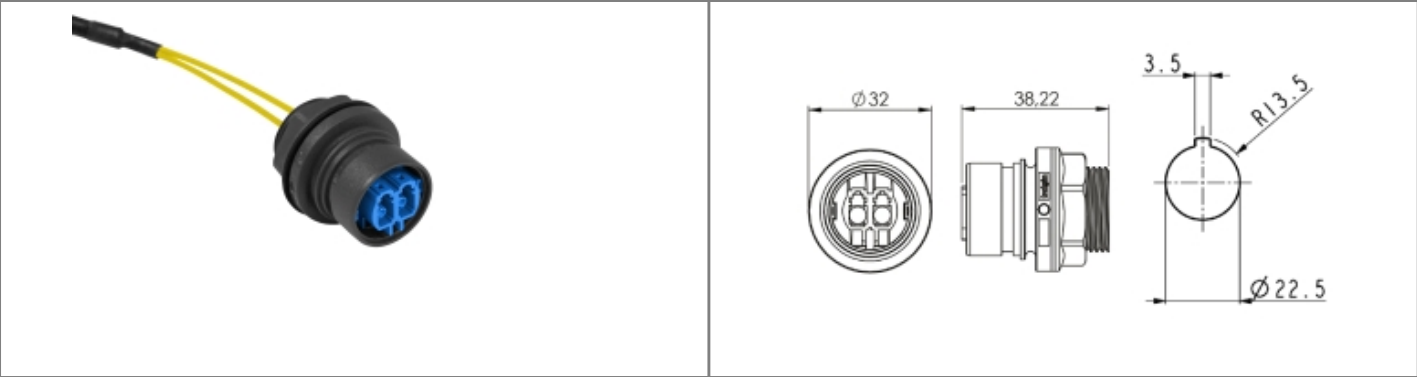

// **Product Description:**

- ⬢ Rear Panel Mount Fiber Connector to LC type connector
 - ⬢ Sealed to IP66, IP68, IP69K when mated with compatible connector
 - ⬢ no cable options, or pre-terminated 1M available
 - ⬢ Duplex LC type fiber connector
- ⬢ Choices of OS1, OM1 and OM3 cables for single or multimode
 - ⬢ PXP6081 Sealing Cap available separately to maintain IP rating of unmated connectors
 - ⬢ Mate with flex fiber connector PXF6050

// **General Information:**

Product Display Title:	Rear Panel Mount Fiber Connector to LC type Connector
Product Family:	Circular Fiber Connectors
Product Series:	6000 Series - Duplex LC Fiber Buccaneer
Body Material:	Polyamide (PA)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	32mm
Fibre Mode:	OS1
Flamability Rating:	UL94V-0
Function:	Rear Panel Mount to Double LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-25°C

// **Product PDF Links**



// **Product 3D CAD Model Links**



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)