


PXF6054AAB Datasheet

Product Name // 10 M, OM3 Multi Mode, Cabled, Flex fiber connector

 [View Product Page](#)

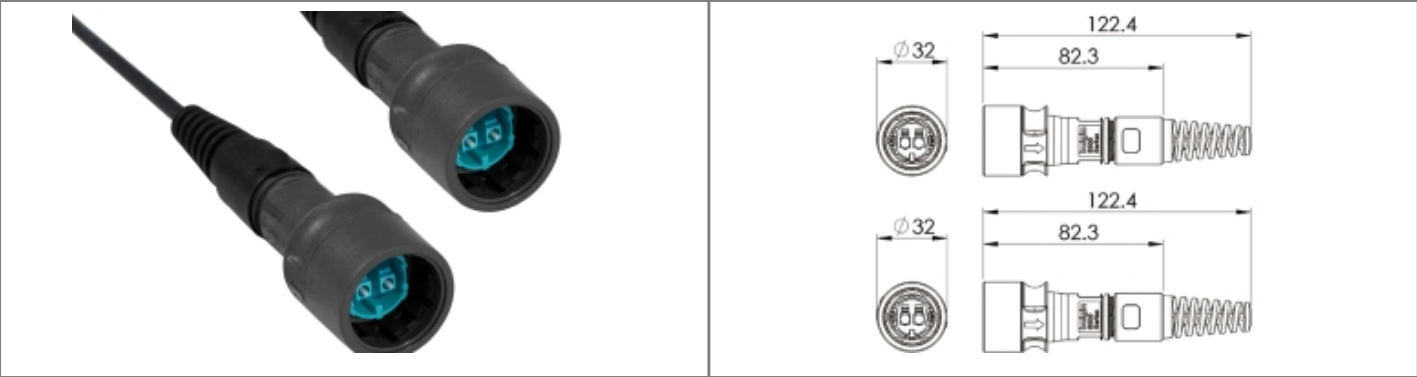

// Product Description:	
- Flex Fiber Connector to Inline Fiber Connector - Sealed to IP66, IP68, IP69K when mated with compatible connector - no cable options, or pre-terminated from 5M - 450M available - Duplex LC type fiber connector	- Choices of OS1, OM1 and OM3 cables for single or multimode - PXP6083 Sealing Cap available separately to maintain IP rating of unmated connectors - Mate with Inline fiber connector or panel mount connectors PXF6051, PXF6052

// General Information:	
Product Display Title:	Flex Fiber Connector to Inline Fiber Connector
Product Family:	Circular Fiber Connectors
Product Series:	6000 Series - Duplex LC Fiber Buccaneer
Body Material:	Polyamide (PA)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	32mm
Fibre Mode:	OM3
Flamability Rating:	UL94V-0
Function:	Flex to Double LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-25°C

// Product PDF Links

 6000 Series Fiber connectors...

// Product 3D CAD Model Links

 PXF6054AAB3D CAD Model