


PXPTPU78FBF03ACL020PUR Datasheet

bulgin
an INFINITI® brand

Product Name // 3 Contacts 7/8" Flex Body Female 2m Cable

 View Product Page

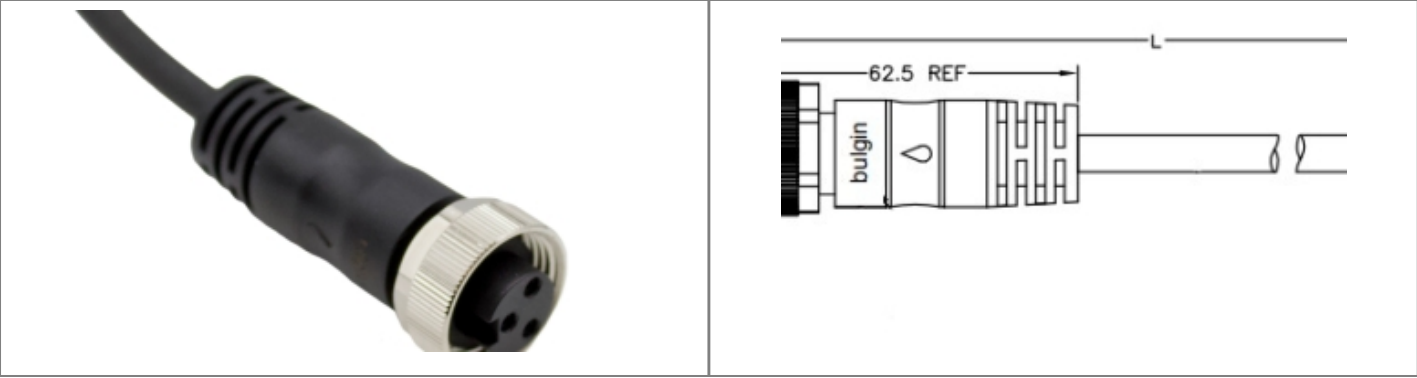

// Product Description:	
 3 Contacts 7-8" Flex Body Female 2m Cable	 Operating Temperature -25°C to +85°C
 IP67 rated when mated	 Rated Voltage 300 V
 Mechanical Cycles >100	 ROHS compliance

// General Information:	
Product Display Title:	7/8" Flex Body Female 2m Cable
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	2m
Connection Method:	Solder
Contact Type:	Socket Contact
Current Max:	12A
Durability:	>100 Cycles
Function:	Flex Body Female Connector Single Ended Cable
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Cable Entry Size:	6.5mm
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links

 78 Series Circular connectors...

// Product 3D CAD Model Links

 PXPTPU78FBF03ACL020PUR3D CAD Model