


SA1019 Datasheet

 [View Product Page](#)

**Product Name // Nickel Plated 12-14 AWG Stamped
Socket Contact - Bandolier**

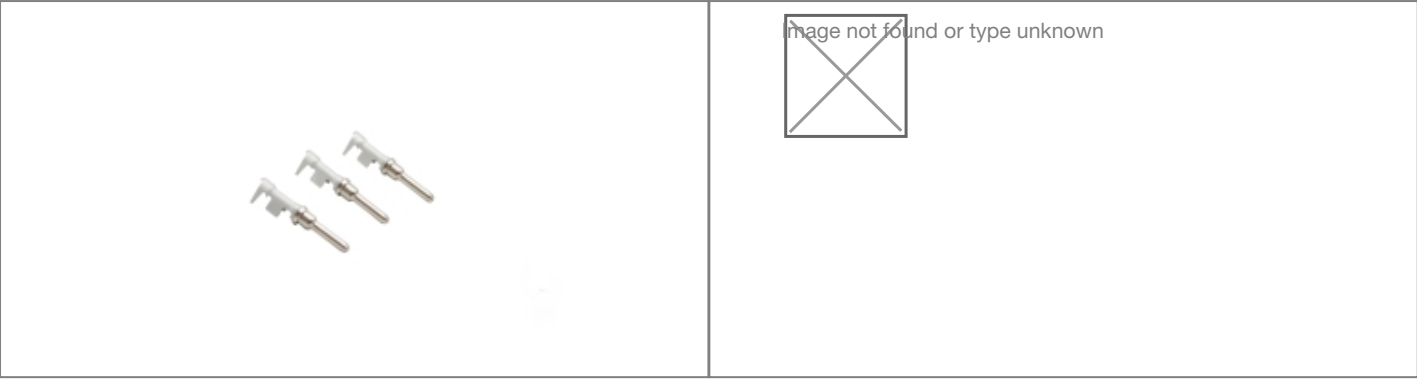

// Product Description:

-  Nickel Plated 12-14 AWG Stamped Socket Contact - Bandolier
-  Crimp Terminals
-  Operating Temperature = -55°C to +125°C

// General Information:

Product Display Title:	Nickel Plated 12-14 AWG Stamped Socket Contact - Bandolier
Product Family:	Rectangular Connectors
Product Series:	Power Rectangular Connectors- Contact - Bandoliers
Body Material:	Cooper Alloy
Contact Type:	Socket Contact - Bandolier Contact - Bandolier
Function:	Crimp Contact - Bandolier
Material Finish:	Nickel Plated Platin-platedg
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	12AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes

// Product PDF Links

 [Rectangular Connector Datasheet](#)

// Product 3D CAD Model Links

 [SA10193D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)