





SA1026 Datasheet

Product Name // Tin Plated 20-22 AWG Stamped Plug Contact - Bandolier

 [View Product Page](#)

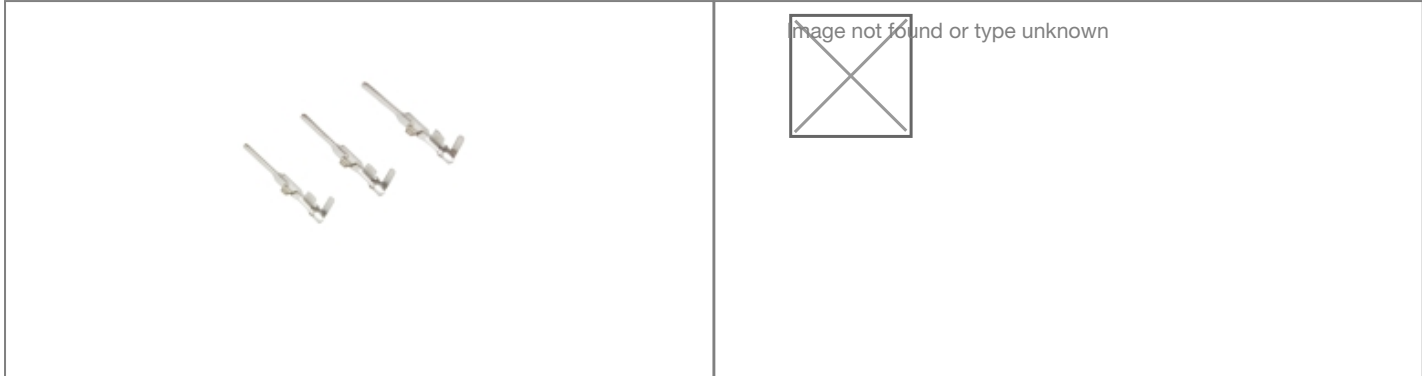


// Product Description:

-  Tin Plated 20-22 AWG Stamped Plug Contact - Bandolier
-  Operating Temperature = -55°C to +125°C
-  Crimp Terminals


// General Information:


Product Display Title:	Tin Plated 20-22 AWG Stamped Plug Contact - Bandolier
Product Family:	Rectangular Connectors
Product Series:	Automotive Rectangular Connectors- Contact - Bandoliers
Body Material:	Cooper Alloy
Contact Type:	Plug Contact - Bandolier Contact - Bandolier
Function:	Crimp Contact - Bandolier
Material Finish:	Tin Plated Plated
Max Contact Accomodation Awg:	22AWG
Min Contact Accomodation Awg:	20AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes


// Product PDF Links

 [Rectangular Connector Datasheet](#)

// Product 3D CAD Model Links

 [SA10263D CAD Model](#)

 Have a question or project enquiry you'd like to talk to us about?

 [Click Here To Contact Us](#)