



SURE-SEAL

Plug



1 Contact

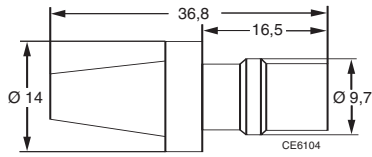

2, 3 and 4 Contacts

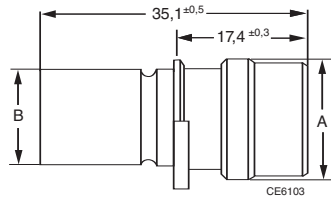


Receptacle

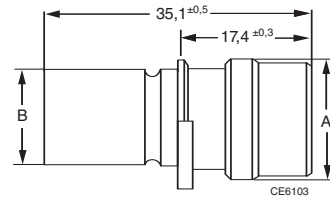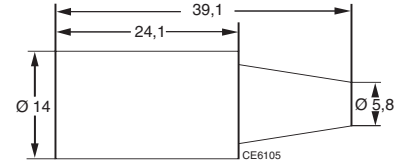


| Shell size | Part No. | A - 0,3 | B - 0,3 | Insulation Ø |
|------------|---------------|------------|------------|-----------------|
| SS1P | 120-1832-000* | | | 2,4 – 3,3 |
| SS2P | 120-8552-000 | 13,9 | 10,9 | 1,8 – 2,8 |
| SS3P | 120-8552-001 | 15,2 | 12,3 | 1,8 – 2,8 |
| SS4P | 120-8552-002 | 15,2 | 12,3 | 1,8 – 2,8 |

*) cable entry 2,4 – 3,3 mm Ø (all others 1,8 – 2,8 mm Ø)

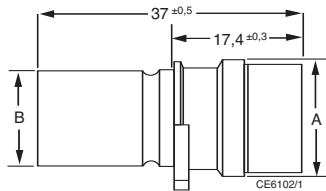

5, 6 and 7 Contacts


| Shell size | Part No. | A - 0,3 | B - 0,3 | Insulation Ø |
|------------|--------------|------------|------------|-----------------|
| SS5P | 120-8552-005 | 25,3 | 20,2 | 1,8 – 2,8 |
| SS6P | 120-8552-006 | 25,3 | 20,2 | 1,8 – 2,8 |
| SS7P | 120-8552-007 | 25,3 | 20,2 | 1,8 – 2,8 |

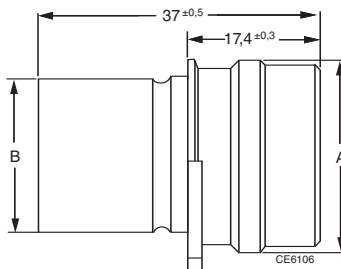


8 to 10 Contacts

| Shell size | Part No. | A ± 0,3 | B ± 0,2 | Insulation Ø |
|------------|--------------|------------|------------|-----------------|
| SS8P | 120-8552-308 | 28,55 | 23,5 | 1,8 – 2,8 |
| SS9P | 120-8552-309 | 28,55 | 23,5 | 1,8 – 2,8 |
| SS10P | 120-8552-310 | 28,55 | 23,5 | 1,8 – 2,8 |

| Shell size | Part No. | A - 0,5 | B - 0,3 | Insulation Ø |
|------------|---------------|------------|------------|-----------------|
| SS1R | 120-1833-000* | | | 2,4 – 3,3 |
| SS2R | 120-8551-000 | 18,0 | 10,9 | 1,8 – 2,8 |
| SS3R | 120-8551-001 | 18,9 | 12,3 | 1,8 – 2,8 |
| SS4R | 120-8551-002 | 18,9 | 12,3 | 1,8 – 2,8 |

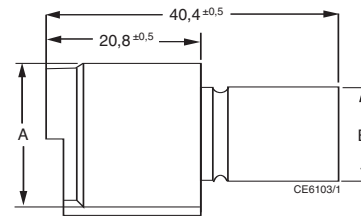

| Shell size | Part No. | A - 0,3 | B - 0,3 | Insulation Ø |
|------------|--------------|------------|------------|-----------------|
| SS5R | 120-8551-005 | 29,1 | 20,2 | 1,8 – 2,8 |
| SS6R | 120-8551-006 | 29,1 | 20,2 | 1,8 – 2,8 |
| SS7R | 120-8551-007 | 29,1 | 20,2 | 1,8 – 2,8 |

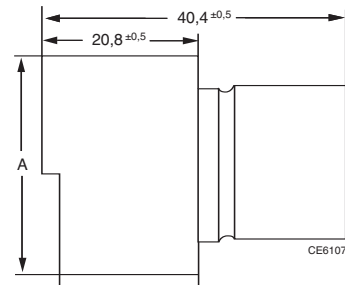

| Shell size | Part No. | A - 0,5 | B ± 0,2 | Insulation Ø |
|------------|--------------|------------|------------|-----------------|
| SS8R | 120-8551-308 | 33,5 | 23,5 | 1,8 – 2,8 |
| SS9R | 120-8551-309 | 33,5 | 23,5 | 1,8 – 2,8 |
| SS10R | 120-8551-310 | 33,5 | 23,5 | 1,8 – 2,8 |