

Plug 90° Solder Termination (Stamped) - U.S. Footprint .318 inch




## Part Numbers



| Shell size | Layout | Plastic Bracket Integrated Grounding Strap, Boardlock, Threaded Insert #4-40 UNC | Plastic Bracket Integrated Grounding Strap, Boardlock, Threaded Insert #4-40 UNC |
|------------|--------|----------------------------------------------------------------------------------|----------------------------------------------------------------------------------|
| DE         | 9      | ZEDEL9PBA                                                                        | ZEDE9PBA                                                                         |
| DA         | 5      | ZEDAL15PBA                                                                       | ZEDA15PBA                                                                        |
| DB         | 25     | ZEDBL25PBA                                                                       | ZEDB25PBA                                                                        |
| DC         | 37     | ZEDCL37PBA                                                                       | ZEDC37PBA                                                                        |

**Note:** For contacts with 30 microinches of gold add -30. Example ZEDEL9PBA-30

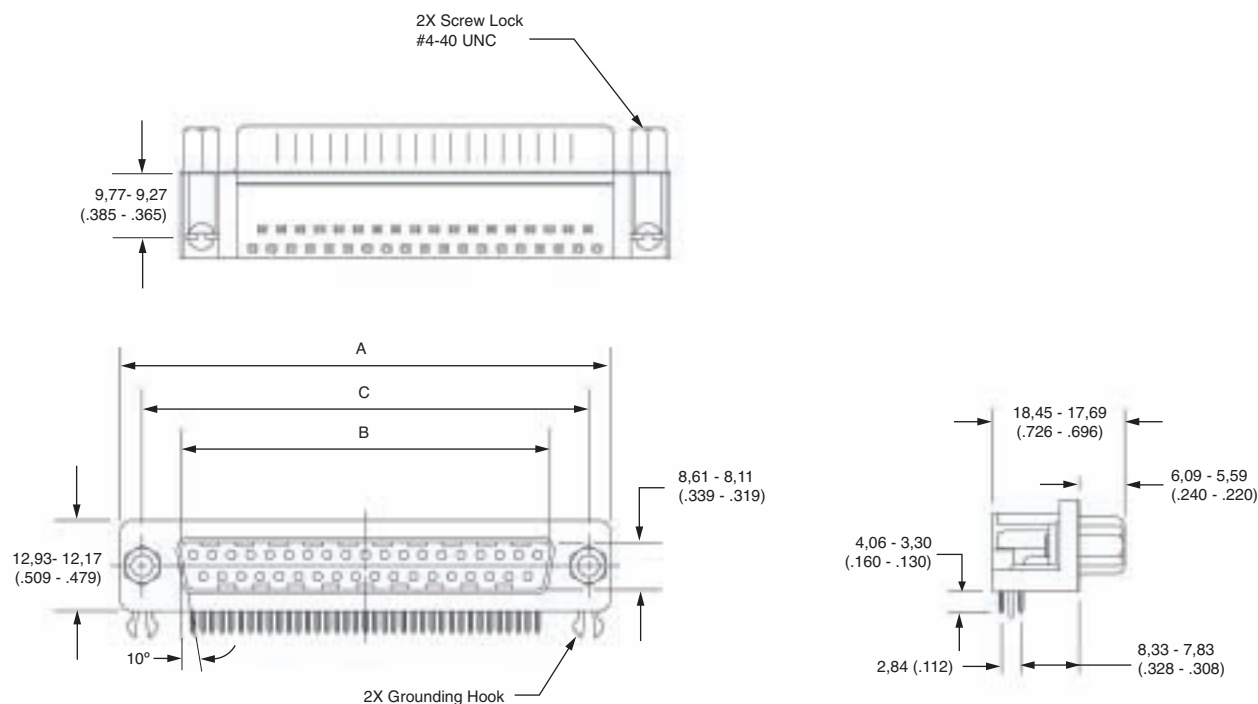

## Dimensions

| Shell size | A<br>±0,38 (.15) | B<br>±0,25 (.010) | C<br>±0,25 (.010) |
|------------|------------------|-------------------|-------------------|
| DE         | 30,89 (1.216)    | 16,92 (.666)      | 24,99 (.984)      |
| DA         | 39,09 (1.539)    | 25,25 (.994)      | 33,32 (1.312)     |
| DB         | 53,09 (2.090)    | 38,96 (1.534)     | 47,04 (1.852)     |
| DC         | 69,40 (2.732)    | 55,42 (2.182)     | 63,50 (2.500)     |