


DUAL TEST ADAPTERS

SPECIFICATIONS

Plug Body - Brass, Nickel Plated (Gold where specified)
Turret Terminals - Brass, Gold or Tin plated as indicated
Rating - For standard (.750 centers) 15 AMP capacity,
5000 WVDC max.


Spring - Beryllium Copper, Nickel Plated (Gold where specified)
Insulation - ABS unless otherwise indicated
Rating - For Miniature (.500 centers) 5 AMP capacity,
2500 WVDC max.

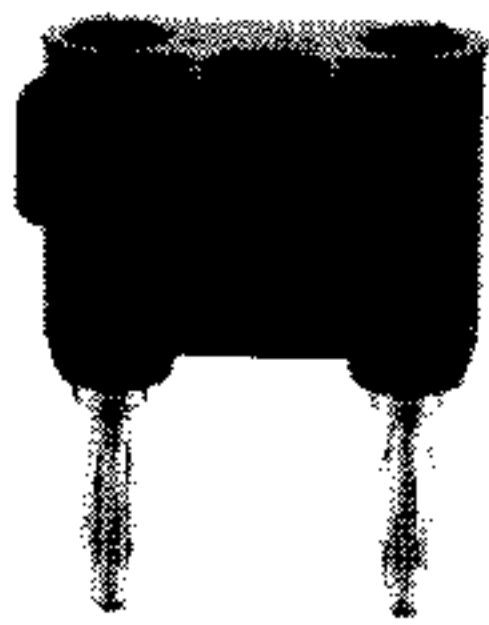

STANDARD DOUBLE BANANA PLUG 25-2550-1-02XX



.750 CENTERS
Nickel plated stacking Banana Plugs/Jacks. Set screws secure leads and /or components. ABS molded insulator. Available in 10 colors (see color chart).

DUAL INSTRUMENT SHORTING BARS

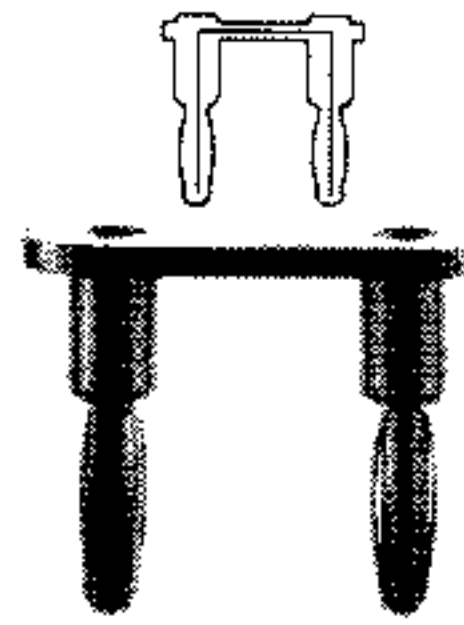

01-2555-1-02

.750 CENTERS
Two standard banana plugs in front are on 3/4" centers. Plug bodies are swaged onto a 3/32" thick brass busbar nickel finished.

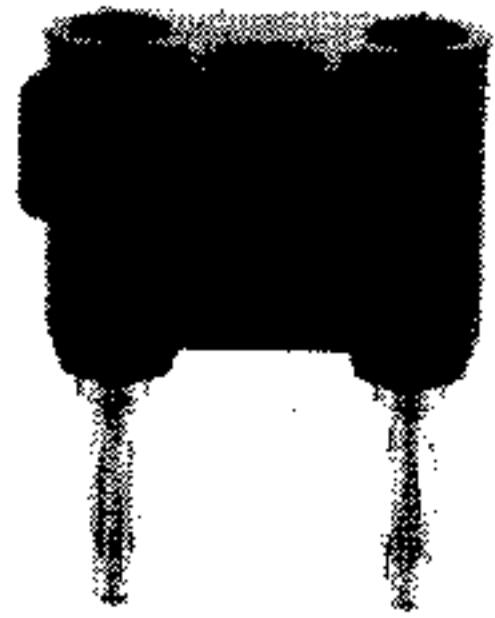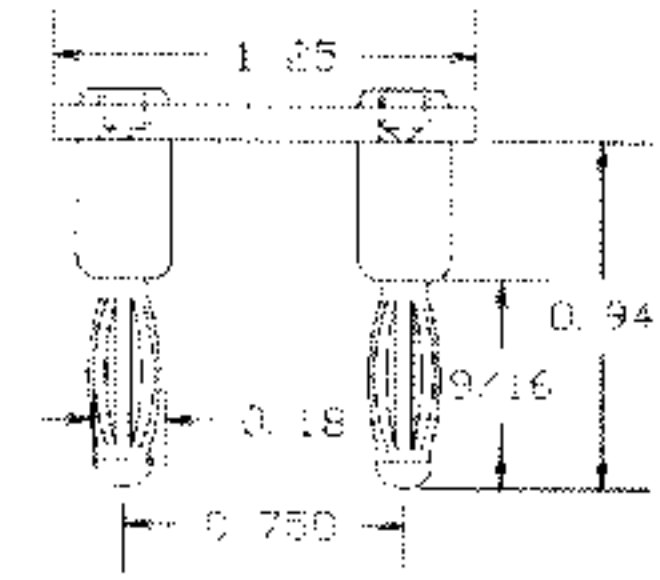

STANDARD DOUBLE BANANA PLUG 25-2550-1-0310 (BLK) 25-2550-1-0312 (RED)


.750 CENTERS
Same as 25-2550-1-02XX except Gold plated banana plugs. Available in Black and Red.

MINIATURE DOUBLE BANANA PLUG WITH SETSCREWS



01-2522-1-0210 (BLK/N.P.) 01-2522-1-0212 (RED/N.P.) 25-2522-1-0310 (BLK/GOLD) 25-2522-1-0312 (RED/GOLD)


.500 CENTERS
Stacking Banana Plugs/Jacks. Setscrews secure leads and/or components. Gold plated banana plug. Available in red and black ABS.

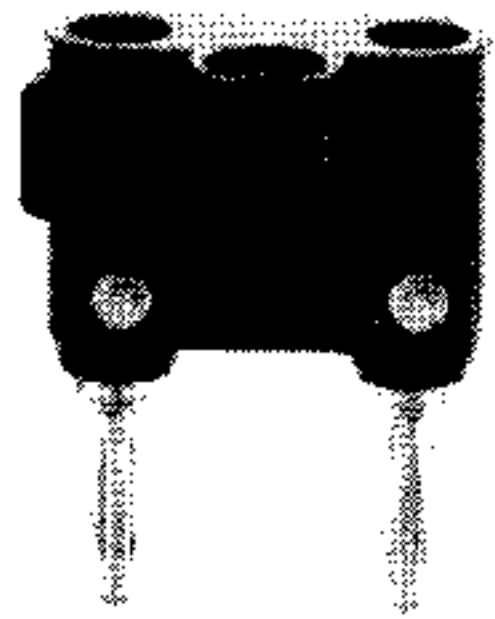

STANDARD DOUBLE BANANA PLUG WITH SOLDER TERMINALS 25-2551-1-0210


.750 CENTERS
Stacking Banana Plugs/Jacks with tin plated turret terminals. For easy permanent connection of cables and /or components. Available in Black polypropylene.

MINIATURE DOUBLE BANANA PLUG WITH SOLDER TERMINAL

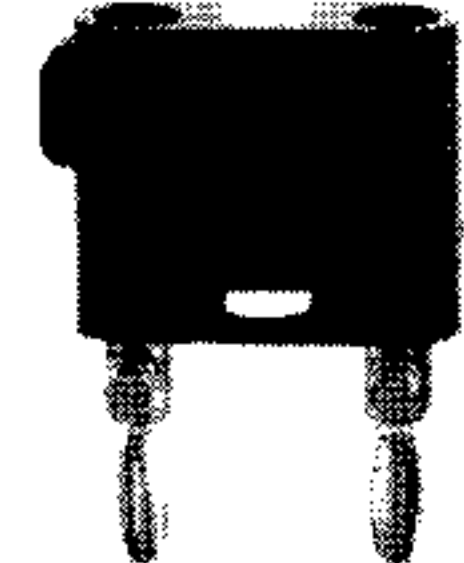

01-2521-1-0210 (BLK/N.P.) 01-2521-1-0212 (RED/N.P.) 25-2521-1-0310 (BLK/GOLD) 25-2521-1-0312 (RED/GOLD)

.500 CENTERS
Solder terminals facilitate quick, permanent, noise free connection of cable and/or components. Available in red or black polypropylene.

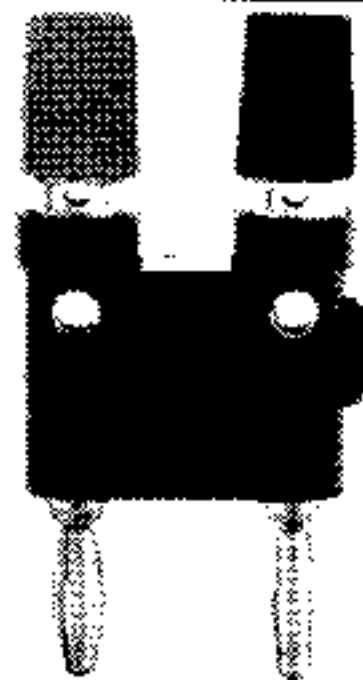


BINDING POSTS DOUBLE BANANA PLUG 25-2557-1-0200

.750 CENTERS
Insulated Dual Binding Post offers stacking feature, comes supplied with one Red and one Black head. Cross holes accept standard banana plugs. Adapter body is black ABS.



MINIATURE DOUBLE BANANA PLUG WITH SHORTING BAR 25-2524-1-0310 (BLK) 25-2524-1-0312 (RED)

.500 CENTERS
Stacking miniature Plug/Jacks gold plated. Available in Red or Black ABS.

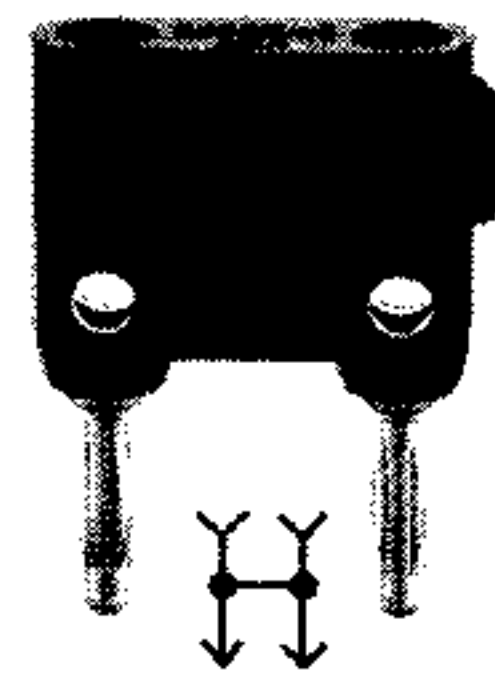


DOUBLE BANANA PLUG WITH MOLDED IN SHORTING BAR 25-2570-1-02XX

.750 CENTERS
Stacking Banana Plugs/Jacks. Available in Red, Black and White ABS (see color chart.)



MINIATURE DOUBLE TIP PLUG WITH SOLDER TERMINALS 25-2526-1-0310 (BLK) 25-2526-1-0312 (RED)

.500 CENTERS
Solder terminals facilitate quick, permanent, noise free connection of cable and/or components. Gold plated terminal and plugs. Available in Red or Black.

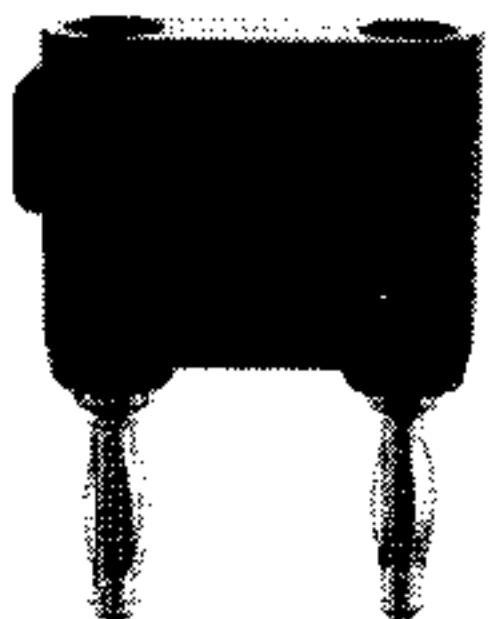

STANDARD DOUBLE BANANA PLUG 25-2573-1-0210 (BLK) 25-2573-1-0212 (RED)

.750 CENTERS
Stacking Banana Plug/Jack. Setscrews secure leads and/or components. Available in Red and Black ABS.



MINIATURE DOUBLE TIP PLUG WITH SHORTING BAR 25-2527-1-0310 (BLK) 25-2527-1-0312 (RED)

.500 CENTERS
Stacking Miniature Tip Plugs/Jacks are gold plated. Available in Red or Black ABS.

BLK	BRN	RED	ORN	YEL	GRN	BLU	PUR	GRY	WHT
10	11	12	13	14	15	16	17	18	19

CONCORD