



Industrial Specification Grade Straight Blade Plugs & Connectors


2-Pole, 3-Wire Grounding
15A, 125V/AC
NEMA 5-15

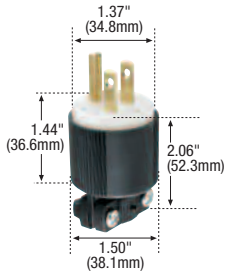


6266

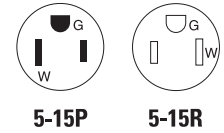

5269N

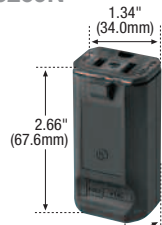

5969BLK

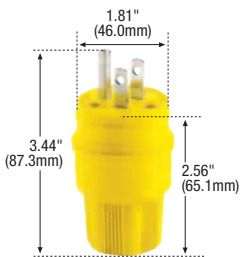

14W47



1547

Industrial Grade Dimensional Information: B-18

Specification Information:

Safety Grip Industrial Plugs & Connectors: B-26

AutoGrip Industrial Plugs & Connectors: B-26

Corrosion Resistant AutoGrip Industrial Plugs & Connectors: B-29

QuickGrip Plugs & Connectors: B-26

Watertight Industrial Plugs & Connectors: B-28

Severe Duty Industrial Plugs & Connectors: B-29

Industrial Grade Plugs & Connectors

Safety Grip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.33-0.66" (6.4-16.7mm)	Black & White	<input type="checkbox"/> 6266	<input checked="" type="checkbox"/> 6269	<input checked="" type="checkbox"/>
			Straight Body 0.33-0.66" (6.4-16.7mm)	Black	<input type="checkbox"/> 6266BLK	<input checked="" type="checkbox"/> 6269BLK	<input checked="" type="checkbox"/>
			Angled Body 0.33-0.66" (7.6-16.7mm)	Black & White	<input type="checkbox"/> 6265	<input checked="" type="checkbox"/>	<input type="checkbox"/>

AutoGrip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.33-0.66" (6.4-16.7mm)	Black & White	<input type="checkbox"/> 5266N	<input checked="" type="checkbox"/> 5269N	<input checked="" type="checkbox"/>
			Corrosion Resistant, Straight Body 0.33-0.66" (6.4-16.7mm)	Yellow	<input type="checkbox"/> 5266NCR	<input checked="" type="checkbox"/> 5269NCR	<input checked="" type="checkbox"/>

QuickGrip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.23-0.72" (5.8-18.3mm)	Black	<input type="checkbox"/> 5965BLK	<input checked="" type="checkbox"/> 5969BLK	<input checked="" type="checkbox"/>

Watertight NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.30-0.65" (7.6-16.5mm)	Yellow	<input type="checkbox"/> 14W47	<input checked="" type="checkbox"/> 15W47	<input checked="" type="checkbox"/>
			Straight Body 0.30-0.65" (7.6-16.5mm)	Black	<input type="checkbox"/> 14W47BK	<input checked="" type="checkbox"/> 15W47BK	<input checked="" type="checkbox"/>

Severe Duty NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.38-1.00" (19.1-25.4mm)	Yellow & Black	<input type="checkbox"/> 1447	<input checked="" type="checkbox"/> 1547	<input checked="" type="checkbox"/>

Icon Key

NAFTA Compliant - see page O-30

Accessories for Industrial Grade NEMA 5-15 Plugs & Connectors

Description	Catalog No.
Watertight plug closure cap for 15A plug	<input type="checkbox"/> 14W <input checked="" type="checkbox"/>
Replacement watertight connector closure cap for 15A connector	<input type="checkbox"/> 15W <input checked="" type="checkbox"/>
Wire mesh grip for 15A watertight plugs & connectors, 0.30-0.50" (7.6-12.7mm) cord dia.	<input type="checkbox"/> WM115 <input checked="" type="checkbox"/>
Wire mesh grip for 15A watertight plugs & connectors, 0.50-0.62" (12.7-15.8mm) cord dia.	<input type="checkbox"/> WM116 <input checked="" type="checkbox"/>



14W



15W



WM115



WM116