


Image gallery

3D view

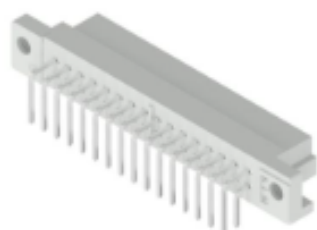

Part No: 122A10559X

Product Description

- DIN EN 60603-2 (DIN 41612)
- Bauform B/2
- Female Connector
- 32-pos.
- Solder pin angled

Inquiry

General Data

Technical Data

Material Data

Downloads

min. working temperature	-55° C
max. working temperature	+125° C
Quality class	Quality class 3
Mating cycles	50
IP rating	IP 20
Contact resistance standard	20 mOhm
Insulation resistance	10 GOhm