


Type D

Female connector
with screw termination
Contact spacing .200"

Directive 2002/95/EC
„RoHS“
Compliant

TECHNICAL DATA

Conductor size: AWG 24 . . . 16
Rated current: 6 A
Rated voltage: 300/250 V~
Moulding material: PBT GV grey
Operating temperature: -55° C to +120° C
Flammability: UL 94-V-O
Contact material: CuSn 6
Contact finish: Au over Ni
Screw connection: steel

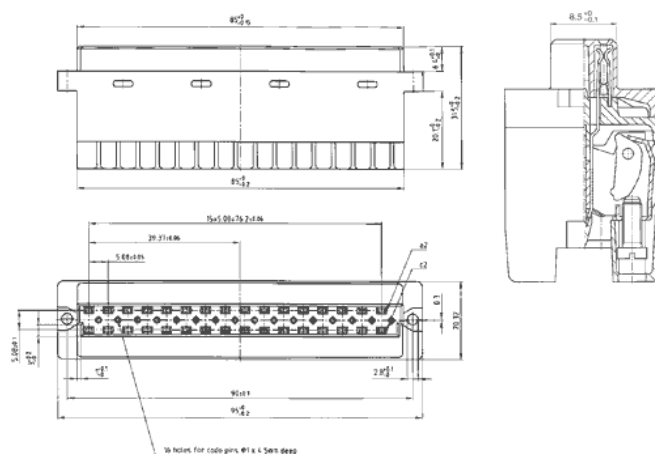

Part Numbers

No. of Pos.	• = contact + = no contact	Female connector with screw termination	
		Pos. 2 4 6 ...	
32	row c	• • • •	122 B 13029 X
	row a	• • • •	