


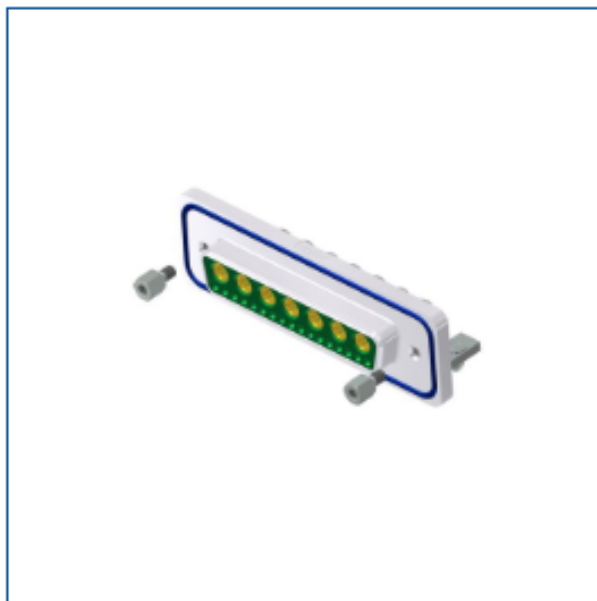

Part No: 15-005733

Product Description

- IP67 Combination D-SUB
- 24W7 [oooooooooooooooooooo]
- Male connector

[Inquiry](#)

General Data	Technical Data	Material Data	Standards	Downloads
Dielectric with standing voltage signal	1000 V			
Dielectric with standing voltage power	1000 V			
min. working temperature	-25° C			
max. working temperature	+105° C			
Working voltage power	250 V			
Quality class	Quality class 3			
Mating cycles	50			
Current rating power	20 A			
Insertion force	55 N			
Extraction force	23 N			
Power resistance standard	2,7 mOhm			