


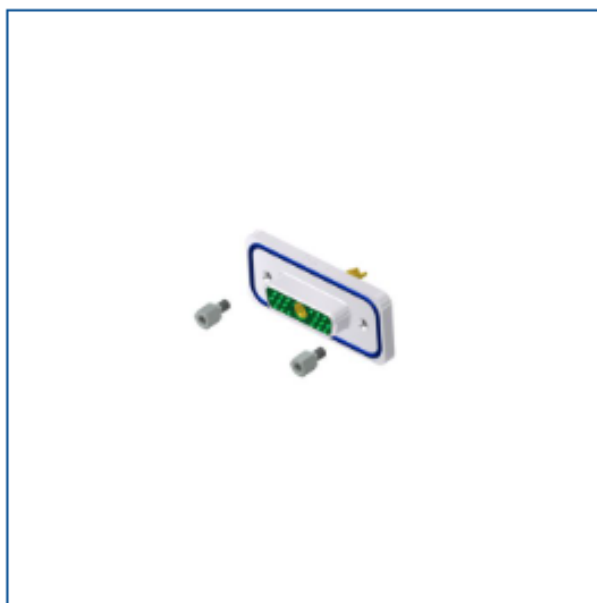

Part No: 15-005903

Product Description

- IP67 Combination D-SUB
- 19W1 [.....o.....]
- Female Connector

[Inquiry](#)

General Data

Technical Data

Material Data

Standards

Downloads

Dielectric with standing voltage signal	1000 V
Dielectric with standing voltage power	1000 V
min. working temperature	-25° C
max. working temperature	+105° C
Working voltage power	250 V
Quality class	Quality class 3
Mating cycles	50
IP rating	IP67
Current rating power	20 A
Insertion force	69 N
Extraction force	11 N
Contact resistance standard	10 mOhm
Power resistance standard	2,7 mOhm