


Image gallery

3D view

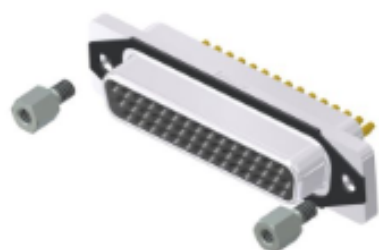

Part No: 15-007693

Product Description

- IP67 D-SUB High Density CONEC SlimCon
- 44-pos.
- Socket
- Solder cup

[Inquiry](#)

General Data

Technical Data

Material Data

Standards

Downloads

Dielectric with standing voltage signal	1000 V
Quality class	Quality class 3
Mating cycles	50
IP rating	IP67 in connected condition
Insertion force	120 N
Extraction force	120 N
Contact resistance standard	10 mOhm
min. working temperature	-40° C
max. working temperature	+105° C