

MINI USB Connector 5pin Solder Type


SPECIFICATIONS

Materials

Insulator: thermoplastic, glass filled, UL 94V-0
 Contacts: Phosphor bronze
 Plated: 30µ" gold plated
 SMD Plated: 120µ" tin plated
 Plastic: PBT
 Shell: Steel nickel plated

Electrical

Insulation Resistance: 1000 MΩ minimum
 Contact Resistance: 30 mΩ Max. initial
 Dielectric Withstanding Voltage: 750V AC for one minute
 Voltage: 30V AC (rms)
 Current: 1.5 Ampere max. per contact at 30°C T-rise
 Temperature: -55°C ~85°C

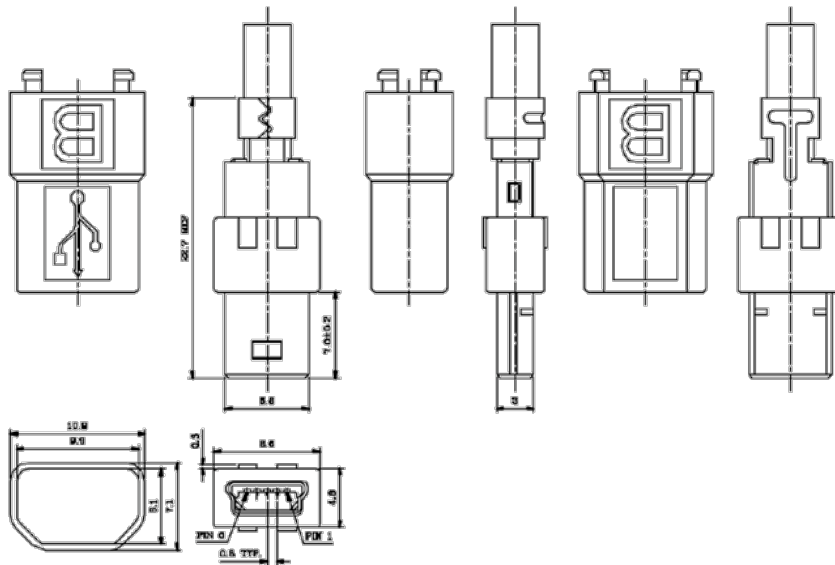

Order Information

33MUB S - 05 P N 0

1 2 3 4 5 6

1. Series No.
33MUB:

3. No. Of Contacts
05: 5 pin

5. Insulator Color
N: Black

2. Terminal Version
S: Solder type

4. Connector Type
P: Male

6. Packaging
0: Packed in bulk



File #: 127344



File #: LR97981