


Image gallery

3D view

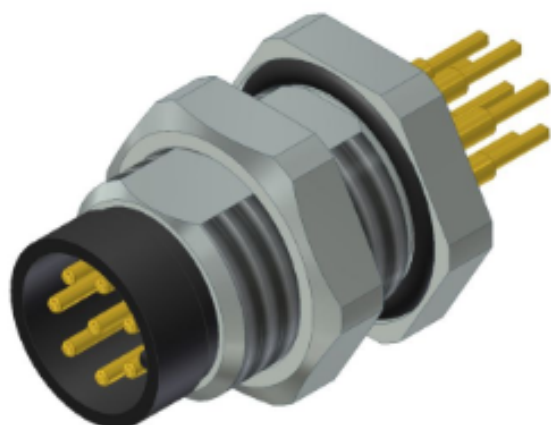

Part No: 42-01163

SAL-8-FSH8-P5,5

Product Description

- Sockets
- Male connector axial
- M8x1
- 8-pos.
- 5,5 mm
- Back panel mounting
- Solder pin straight
- A-coded
- Unshielded

Inquiry

General Data

Technical Data

Material Data

Standards

Downloads

Shielding	Unshielded
min. working temperature	-30° C
max. working temperature	+80° C
Pollution degree	3/2
IP rating	IP67 in mated condition
Sealing material	NBR
Mating cycles	>=100
Recommended torque	0,6- 0,8 Nm
Insulation resistance	>=100M Ohm