


REV. 1 7/17/92

| | |
|------------------------|---------------------|
| COIL: \ominus +25 °C | |
| RESISTANCE | 2074 OHMS \pm 10% |
| NOMINAL VOLTAGE | 26.5 VDC |
| MUST OPERATE | 14.4 VDC |
| MUST RELEASE | 1.4 VDC |

CUSTOMER DATA SHEET

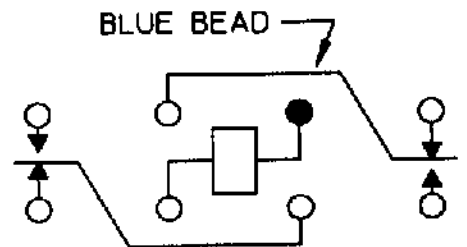

| | |
|--------------|-----------------------------|
| ENVIRONMENT: | |
| VIBRATION | 10 CPS TO 2000 CPS @ 20 g's |
| SHOCK | 100 g's 6 MS. DURATION |
| TEMPERATURE | -65 °C TO +125 °C |

CONTACT RATING: LOW LEVEL TO 2A
 30 VDC RESISTIVE 75A 30 VDC INDUCTIVE
 100,000 OPERATIONS MIN.

NOTES: OPERATE 5 MS MAX.
 RELEASE 3 MS MAX.
 BOUNCE 3 MS MAX.

DR. R.B. 5/19/92 CK. 7/17/92

COMMUNICATIONS INSTRUMENTS, INC.

CUST. Hi-G
 CUST. NO. 2KA-2A-126P

TYPE "HMS" RELAY

HMS1201S62