

REV. 1
DCO 170580


CUSTOMER DATA SHEET

COIL: @ 25°C
RESISTANCE: 2500 OHMS ± 10%
NOMINAL VOLTAGE: 28 VDC
MUST OPERATE

8.0 mADC

4.0 mADC

2.0 mADC MAX, 0.4 mADC MIN

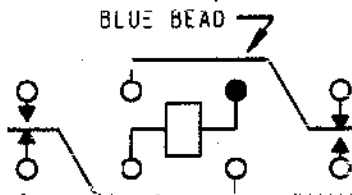

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS @ 28 VDC RESISTIVE
100,000 OPERATIONS

DR: BSH 10/11/01 CK: TLG 10-11-01

CII Technologies
advanced control electronic solutions

3SAT1347A2

MUST RELEASE

ENVIRONMENT

VIBRATION

SHOCK

TEMPERATURE

NOTES:

CUSTOMER NO.

CUSTOMER NO.

F-718 REV. 3

OPERATE 15 MS MAX
RELEASE 10 MS MAX
CONTACT BOUNCE 2 MS MAX

QPL
M5757/3-130 REV. 3SAT RELAY