


REV. 3
DCO 63333

COIL: @ 25°C	
RESISTANCE	390 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC @ 25°C
MUST RELEASE	1.4 VDC @ 25°C

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: TERMINALS ARE GOLD PLATED	
OPERATE & RELEASE 5 MS MAX.	
BOUNCE 5 MS MAX.	

CUSTOMER DATA SHEET

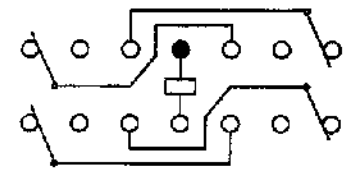

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 2 AMP 28 VDC RESISTIVE

DR. R.B. 11/29/90 CK. TLG 10-24-00



CUST. CII STD
CUST. NO. REV.

'SRBW' RELAY

SRBW-4C-24G